




Hubbell Premise Wiring

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Riser Rated, Spool, Pink

By Hubbell Premise Wiring
Catalog Number [C6FTPSRPK](#)

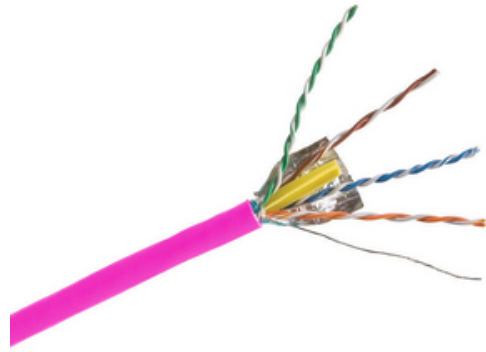

Copper Solutions, Cable, Cat6, Foil Twisted Pair, 10 Gig, Riser Rated, Spool, Pink.

Application

Riser

General

Construction	Copper/Insulation Eccentricity Shall Be 90% Minimum
Data Transfer Rate	1GbE, Limited 10GbE
Debris Shield Type	Foil Tape
EU RoHS Indicator	Yes
Item Type	NEXTSPEED Category 6 FTP Cable
Material - Jacket	Low Smoke PVC
Temperature Rating	-20oC to +50oC (-4oF to +122oF)
UPC	662620211602

Electrical Ratings

Impedance 100

Conductor Related

Conductor Size	#23 AWG
Conductor Type	Solid Bare Copper
Nema Color	Pink
Pairs Or Conductor	4-Pair

Logistics

Carton Quantity 1000



A proud member of the Hubbell Family.