


HUBBELL Premise Wiring

USOC XCELERATOR™ Series Jack

By Hubbell Premise Wiring
Catalog # [HXJUOR](#)

Telephone/Data Jack, XCELERATOR, USOC 6-Position

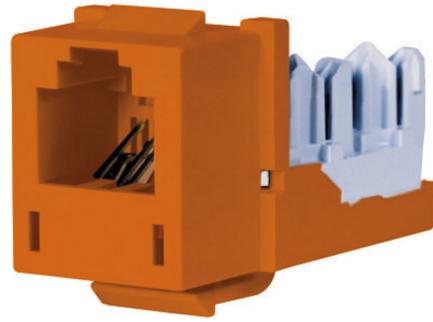

Features

- RJ-25 USOC (RJ-25) Jack
- Exclusive 1-Punch Termination Reduces Termination Time by 75%
- Mating Cycles Exceed Industry Standard by Four Times
- Bulk Packaging Reduces Excess Waste on the Job

Application

Telephone

Performance

USOC

Specifications

Environmental Conditions	Indoor Dry Unless Protected By Additional Means
EU RoHS Indicator	Yes
Industry Standard(s)	<ul style="list-style-type: none">• 6-Position USOC Compliant• CSA Certified• Mechanical TIA-568• RoHS Compliant• UL Listed 1864

Conductor

Contact	IDC: Phosphor Bronze with 100 Micro-Inch Tin Over Plating
---------	---

Current

Withstand Voltage	1,000 Vac @ 60 Hz
Connectivity	RJ45 Jack to IDC Punch Down
Contact Resistance	Per TIA
Insertion Loss	2000

Dimensions

Display Size	Standard Sized Product
Size	0.86 (22) x 0.67 (17) x 1.29 (33)

General

Series	XCELERATOR™ Series
Style	RJ-45 Jack
Color	Orange
Construction Material - Main Item Type	Thermoplastic Modular Jack
Material - Mounting Hardware Type	Hubbell Keystone Modular Jack
Contact Point Material	Beryllium Copper with Gold Over Plating
Specifications	<ul style="list-style-type: none">• Housing - High impact thermoplastic (UL 94 V-0)• IDC Contact - Phosphor bronze with 100 micro-inch tin over nickel under plating• Nose Contact - Beryllium copper with precious metal plating with nickel under-plating
Material - Housing	High-impact thermoplastic (UL 94V-0)
UPC	662620824734
Mounting Type	Snap-fit

Logistics

Number of Pieces in Package	1
Carton Quantity	25

Operational

Temperature Rating	Max Continuous- 75° C, Minimum- -40° C Without Impact
Operating Cycles	2000 Plug

Product Assets

[Catalog \[English\]](#)
[Catalog Page \[English\]](#)
[Catalog Page \[English\]](#)