


Catalog # **NS721W**

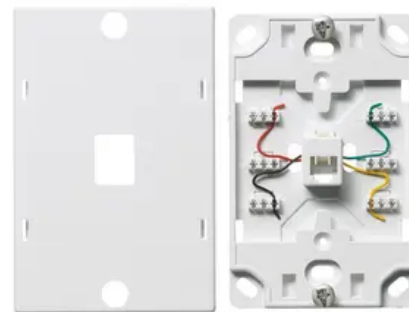

Plates, Wall Phone, 6-Position 4- Conductor, 110 Block, White

- Meets FCC part 68
- Available in high impact-resistant thermoplastic or stainless steel

Communications

Catalog Number	NS721W
Color	White
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 4-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Specifications	Device Type - 6-Position, 4-Conductor

Type
UPC

Max Continuous- 75 Degrees C,
Minimum- -40 Without Impact
Telephone Jack
883778502613

Display Size

Standard Sized Product

- Connectivity
- Contact Resistance
- Insertion Loss

110 Punch Down
Per TIA
Per TIA

Industry Standard(s)

UL Listed

Carton Quantity

10

[Specifications - NS721W Specification Sheet French](#)
[Specifications - NS721W Specification Sheet English](#)