


Plates, 1-Gang, With Jack, 6-Position 6-Conductor, Screw Terminal, White

Plates, 1-Gang, With Jack, 6-Position 6-Conductor, Screw
Terminal, White

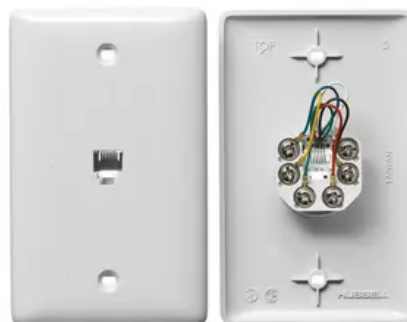

- Meets FCC part 68
- Convenient screw down terminals
- High impact-resistant thermoplastic plate

Communications

General

Catalog Number	NS732W
Color	White
Contact	Phosphor Bronze
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	1) 6-Position 6-Conductor Jack
Material	Nylon
Material - Mounting Hardware	Screw Mounting
Size	Standard
Specifications	• Device Type - 6-Position, 6-Conductor • Style - Standard
Temperature Rating	Max Continuous- 75 Degrees C, Minimum- -40 Without Impact

Voice
883778501371

Display Size Standard Sized Product

Connectivity	Screw Terminals
Contact Resistance	Per TIA
Insertion Loss	Per TIA

Industry Standard(s)	UL Listed
----------------------	-----------

Carton Quantity 10

Product Assets

[Catalog Page - PREM T9 CatalogPage](#)
[Catalog Page - PREM V14 Catalog Page](#)
[Catalogs - Premise Wiring Catalog](#)
[Specifications - NS732W Specification Sheet English](#)
[Specifications - NS732W Specification Sheet French](#)