


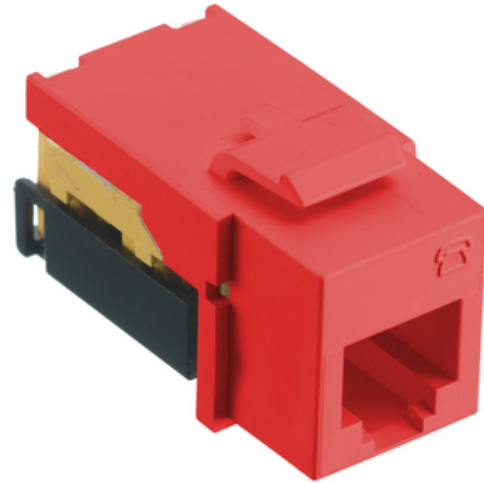

USOC netSELECT™ Jack

By Hubbell Premise Wiring
Catalog Number [NSJUR](#)

NetSELECT™ RJ25 USOC modular jacks support various telephony applications. The innovative angled QuickLace™ termination towers provide ample room for lacing, accelerating the termination.



Features

- Easy To Terminate Angled Wiring Towers
- RJ25 USOC Telephone Jack

Application

Telephone

General

Color	Red
Construction Material - Main Contact	Thermoplastic IDC: Phosphor Bronze with 100 Micro-Inch Tin Over Plating
Contact Point Material	Beryllium Copper with Gold Over Plating
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Modular Jack
Material - Housing	High-impact thermoplastic (UL 94V-0)
Material - Mounting Hardware	Screw Mounting
Mounting Type	Snap-fit
Operating Cycles	750+ Plug
Performance	USOC
Series	USOC
Size	0.86 (22) x 0.67 (17) x 1.29 (33)
Style	RJ-45 Jack
Temperature Rating	Max Continuous- 75° C, Minimum- -40° C Without Impact
Type	Modular Jack
UPC	883778503115

Dimensions

Display Size Standard Sized Product

Electrical Ratings

Connectivity	RJ45 Jack to IDC Punch Down
Contact Resistance	Per TIA
Insertion Loss	Per TIA
Withstand Voltage	1,000 Vac @ 60 Hz

Certifications and Compliance

Industry Standard(s)	<ul style="list-style-type: none">• 6-Position USOC Compliant• CSA Certified• Mechanical TIA-568• RoHS Compliant• UL Listed 1871
----------------------	--

Logistics

Carton Quantity	25
Number of Pieces in Package	1

Product Assets

[Catalog Page - Premise Catalog Page V-10](#)



A proud member of the Hubbell Family.

©2023 Hubbell Incorporated. All rights reserved.
PREM_CA-NSJUR-SPEC-EN | REV 5/2023