


HUBBELL Premise Wiring

Patch Cord, Cat 5e, 110/110, Yellow, 3' Length

By Hubbell Premise Wiring
Catalog # [PC110C5EL3](#)

Patch Cord, Cat 5e, 110/110, Yellow, 3' Length

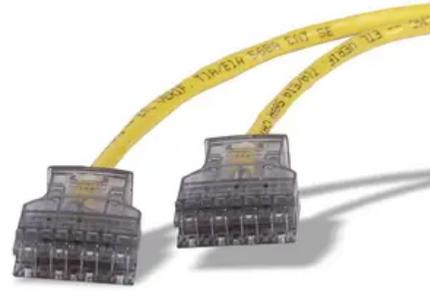

Features

- Plug Housing Includes Built-In Polarization to Ensure Proper Mating Connection to Connecting Blocks
- Angled Conductor Towers Separate Paired Conductors and makes Pair Splitting and Conductor Lacing Simple
- Cable Ties Secure Cable to Cover for Easy Termination and Strain Relief
- Clear Gray or Yellow Keeps Conductors Visible During and After Termination

Performance

Electrical - Terminates 24 to 26 AWG solid or 7-strand twisted-pair cable -

General

Attenuation	.1dB
Boot Type	Polycarbonate
Catalog Number	PC110C5EL3
EU RoHS Indicator	Yes
Item Type	SPEEDGAIN 110 Connecting Block System
Material - Insulation	Flame Redardant PVC
Material - Jacket	Flame Redardant PVC
Plug Type	110 Punch Down
Series	Cat 5E
Specifications	Material - Polycarbonate UL 94V-0

Temperature Rating UPC	Per TIA 662620835976
---------------------------	-------------------------

Dimensions

Outside Diameter	0.218
------------------	-------

Electrical Ratings

Voltage Rating	600V AC kV
----------------	------------

Conductor Related

Conductor Stranding	Stranded
Conductor Type	Copper
Number of Conductors	8-Conductor
Wire Size	#26-22 AWG

Certifications And Compliance

Industry Standard(s)	Exceeds TIA/EIA-568-C.2-1 Category 6 ConNEcting Hardware Specifications
----------------------	---

Logistics

Carton Quantity	20
-----------------	----

Product Assets

- [Specifications - PC110C5EL3](#)
- [Specifications - PC110C5EL3 Specification Sheet English](#)