


HUBBELL Premise Wiring

Patch Cord, 10Gig, PC6A, Blue, 3' Length

By Hubbell Premise Wiring
Catalog # [PC6AB03](#)

Patch Cord, 10Gig, PC6A, Blue, 3' Length

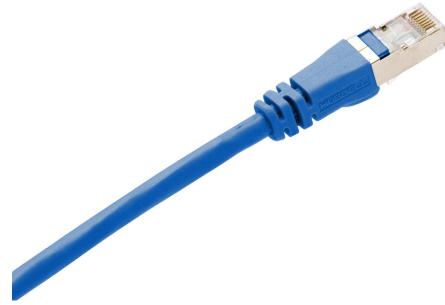

Features

- 10GbE Application Assurance
- Maximum Bandwidth Beyond 625MHz
- Component Compliant ANEXT Performance
- Qualified to 150% of 802.3bt PoE Current Level

Specifications

EU RoHS Indicator	Yes
Industry Standard(s)	<ul style="list-style-type: none">• ANSI/TIA/EIA-568-C.2 Category 6A Component• ISO 11801/60603-7-41 Category 6A Component

Conductor

Wire Size	#24 AWG
Number Of Conductors	8-Conductor
Conductor Type	Copper
Conductor Stranding	Stranded

Current

Voltage Rating	300V AC kV
----------------	------------

Dimensions

Outside Diameter	0.218
Length	3 ft

General

Plug Type	RJ45
Color	Black
Type	Shielded
Material - Jacket	Flame Redardant PVC
Material - Insulation	Flame Redardant PVC
Specifications	<ul style="list-style-type: none">• Conductor - 26AWG FTP• Contact Plating - 50 micro-inch Gold with 100 micro-inch under plating• Jacket - Flame-Retardant PVC-CM Rated• Plug Body - Polycarbonate UL 94V-0• Plug Boot - PVC
UPC	662620203997

Logistics

Carton Quantity	200
-----------------	-----

Operational

Temperature Rating	Per TIA
--------------------	---------

Product Assets

- [Catalog \[English\]](#)
- [Catalog Page \[English\]](#)
- [Catalog Page \[English\]](#)