


# HUBBELL Premise Wiring

## USOC XCELERATOR™ Jack

By Hubbell Premise Wiring  
Catalog # [HXJUOW](#)

Telephone/Data, Jack, XCELERATOR, USOC 6-Position

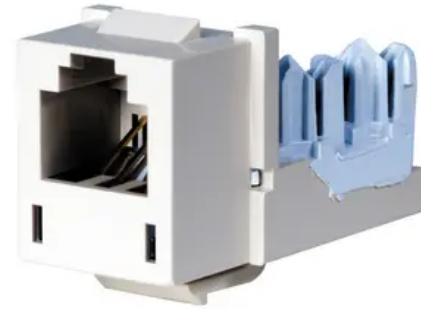

### Application

- Telephone

### Performance

USOC

### General

Catalog Number	HXJUOW
Color	Office White / Light Almond
Construction Material - Main Contact	Thermoplastic IDC: Phosphor Bronze with 100 Micro-Inch Tin Over Plating
Contact Point Material	Beryllium Copper with Gold Over Plating
EU RoHS Indicator	Yes
Environmental Conditions	Indoor Dry Unless Protected By Additional Means
Item Type	Modular Jack
Material - Housing	High-impact thermoplastic (UL 94V-0)
Material - Mounting Hardware	Keystone
Mounting Type	Snap-fit
Operating Cycles	2000 Plug
Series	USOC
Size	0.86 (22) x 0.67 (17) x 1.29 (33)
Specifications	<ul style="list-style-type: none"><li>• Housing - High impact thermoplastic (UL 94 V-0)</li><li>• IDC Contact - Phosphor bronze with 100 micro-inch tin over nickel under plating</li><li>• Nose Contact - Beryllium copper with precious metal</li></ul>

plating with nickel under-plating

Style  
Temperature Rating

RJ-45 Jack  
Max Continuous- 75° C,  
Minimum- -40° C Without Impact

Type  
UPC

Modular Jack  
662620824710

### Dimensions

Display Size

Standard Sized Product

### Electrical Ratings

Connectivity  
Contact Resistance  
Withstand Voltage

RJ45 Jack to IDC Punch Down  
100 Ohm  
1,000 Vac @ 60 Hz

### Certifications And Compliance

Industry Standard(s)

- 6-Position USOC Compliant
- CSA Certified
- Mechanical TIA-568
- RoHS Compliant
- UL Listed 1864

### Logistics

Carton Quantity 25  
Number of Pieces in Package 1

### Product Assets

[Literature - HDPJ High Density Jack Panels Specifications - HXJUOW](#)