

DFS SERIES

LED Decorative Square Drum

Specifications:

Description:

Family offering of ceiling, cable pendant, and wall mount decorative fabric/acrylic diffusers. The DFS Series combines modern aesthetics and quality performance by offering a wide array of choices for size, shape and material finish. With the possibility for custom sizes and finishes, this offering is sure to meet every design need. Ideal for hospitality, multi-family, commercial, and residential applications.

Features:

- Family offering of surface mount, cable pendant mount and accompanying sconces.
- Fabricated square drum shade uniquely crafted with a outer laminated fabric material.
- Shade sizes of 12", 15" and 19". Five fabric and acrylic finish options available.
- Integrated with high performance LED light engine rated at 50,000 hours, 3000K, 90 CRI
- Cable pendant mount option with white and nickel finish choices.

Specifications:


- **Construction:** Light weight, full acrylic decorative shade with outer layer of decorative fabric. Option of double laminated fabric material allows for a durable and cleanable surface finish. Shades attach to a metal pan chassis that includes a high performance LED integrated module. LED integrated module includes spread optics to provide clean and even distribution on all surface areas of decorative shade.
- **Installation/Mounting:** Surface housing option to be installed ceiling mount to standard 4" recessed outlet box. Cable pendant housing option supplied with canopy mount and 10ft of cable/cord. Canopy to be installed ceiling mount to standard 4" recessed outlet box. Mounting screws for outlet box included. Shade attaches to chassis via 3 mounting pins, included.
- **Electrical:** 120V/60 Hz., dimmable to 10%
- **Listing:** cULus label for Damp Locations. 5 Year limited warranty.

Images:



Dimensions:

	A	B
12	4.5"	12.25"
15	4.5"	15"
19	4.5"	19.25"

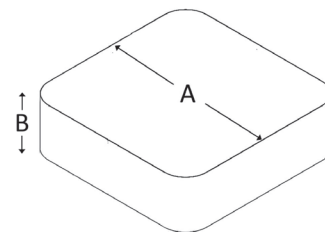

Performance:

	15" Surface Mount	19" Surface Mount
Lumens	1763	1710
Watts	25.6	32.3
Amps	0.224 / 0.097	0.277 / 0.120

** Above data based on WTL finish

Catalog Number:

Series	Mounting	Shape	Size	Shade Finish	Wattage	Voltage	CRI/ CCT	Canopy Finish
PCDFS - Decorative Fabric Shade	SM - Surface Mount	SQ - Square Drum	12 - 12"	WTL - White Linen	17 - 17W ¹	120V - 125V/60Hz	930 - 90CRI/ 3000K	Blank (surface mount) WT - White ⁴ BN - Brush ⁴ Nickel
			15 - 15"	BGL - Beige Linen	25 - 25W ²			
	CM - Cable Pendant Mount	19 - 19"	BKL - Black Linen	32 - 32W ³				
			GYL - Gray Linen					
			LWT - Double Laminated White Linen					
			LBG - Double Laminated Beige Linen					

¹ - Wattage specific to 12" size only

² - Wattage specific to 15" size only

³ - Wattage specific to 19" size only

⁴ - CM mounting only

Project: _____
 Fixture Type: _____
 Location: _____
 Contact: _____

DFS SERIES

LED Decorative Inner Step Round Drum

Shade Finish Options:



Full Acrylic White White Linen Beige Linen Gray Linen Black Linen

Canopy Finish Options:



Brushed Nickel White

Additional Images:



PCDFS-SM-SQ-12-WTL



PCDFS-SM-SQ-12-BKL



PCDFS-SM-SQ-19-WTL



PCDFS-CM-SQ-12-WTL



PCDFS-CM-SQ-12-BKL



PCDFS-CM-SQ-19-WTL



PCDFS-SM-SQ-15-WTL



PCDFS-SM-SQ-15-BGL



PCDFS-SM-SQ-15-GYL



PCDFS-CM-SQ-15-WTL



PCDFS-CM-SQ-15-BGL



PCDFS-CM-SQ-15-GYL