

FLUORESCENT STRIP SERIES

Strip Lighting

Specifications:

Features:


- Steel construction with a white painted finish
- Horizontal or vertical mounting, ceiling or wall
- ½" KO on each end cap for continuous row and on KO on each side near ends
- Mounting KO's near each end on the back plate
- 120 V, 50/60 Hz NPF electronic ballast
- Bi-pin twist and lock sockets on attached flip bracket for ease of installation
- P7265 & P7266 0°F minimum start temperature
- P7267 & P7268 32°F minimum start temperature
- Lamp end-of-life protection, manual reset

Compliances:

The Fluorescent Strip Series is UL-CUL Damp location listed.

Dimensions:

Images:

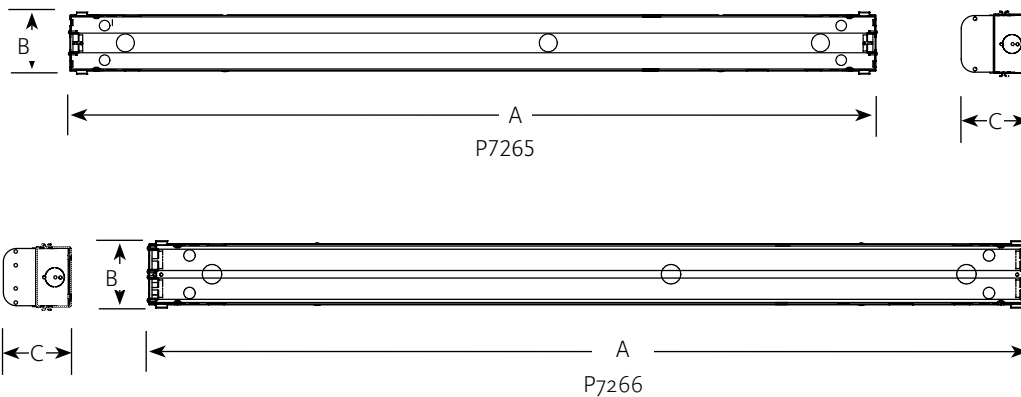

Model	A	B	C
P7265 - 30EB	24"	3"	3 1/8"
P7266 - 30EB	24"	3"	3 1/8"
P7267 - 30EB	48"	3"	3 1/8"
P7268 - 30EB	48"	3"	3 1/8"

Catalog number:

Model	Finish	Number of Lamp & Type
P7265	30EB - White, Baked Enamel	1 - 17W T8
P7266		2 - 17W T8
P7267		1 - 32W T8
P7268		2 - 32W T8