

Briarwood

Ceiling downrod Mounted • Damp Location Listed

Description:

Briarwood Collection 22-Inch 3-Blade Galvanized AC Motor Farmhouse Ceiling Fan


Specifications:

- Fully dimmable with dimmable bulbs
- Canopy covers a standard 4" recessed outlet box: 7.25 in W., 2 in ht., 7.25 in depth
- Mounting Bracket
- 45 in of wire supplied

Performance:

Number of Lamps	4
Input Power	5.5 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	500/90 (LM-79)
CCT	2200 K
CRI	80 CRI
Life (hours)	15000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	Limited Lifetime warranty
Labels	cETLus Damp Location Listed
	AC motor

P250067-141-WB

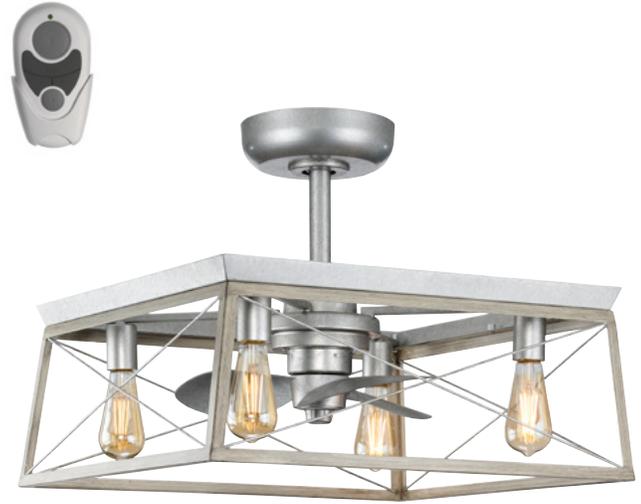

Dimensions:

Length: 22 in
 Depth: 22 in
 Height: 17 in

ENERGYGUIDE

**Estimated
Yearly Energy Cost**

\$9

\$3
\$34

Cost Range of Similar Models (19" – 84")

• Based on 12 cents per kWh and 6.4 hours use per day
 • Your cost depends on rates and use
 • Energy Use: 31 Watts

Airflow

1,145

Cubic Feet Per Minute

• The higher the airflow, the more air the fan will move
 • Airflow Efficiency: 37 Cubic Feet Per Minute Per Watt

All estimates based on typical use, excluding lights ftc.gov/energy