

Air Pro Builder Fan

Ceiling downrod Mounted • Dry Location Listed

Description:

Air Pro 52 in. White 5-Blade AC Motor Transitional Ceiling Fan

Specifications:

- Canopy covers a standard 4" recessed outlet box: 5 in W., 2.25 in ht., 5 in depth
- Hdwr. Included
- 80 in of wire supplied

Performance:


Input Frequency	60 Hz
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	30-year Limited Warranty
Labels	UL Dry Location Listed
	AC motor

P250080-030



Dimensions:

Length: 52 in
 Diameter: 52 in
 Height: 12-1/2 in

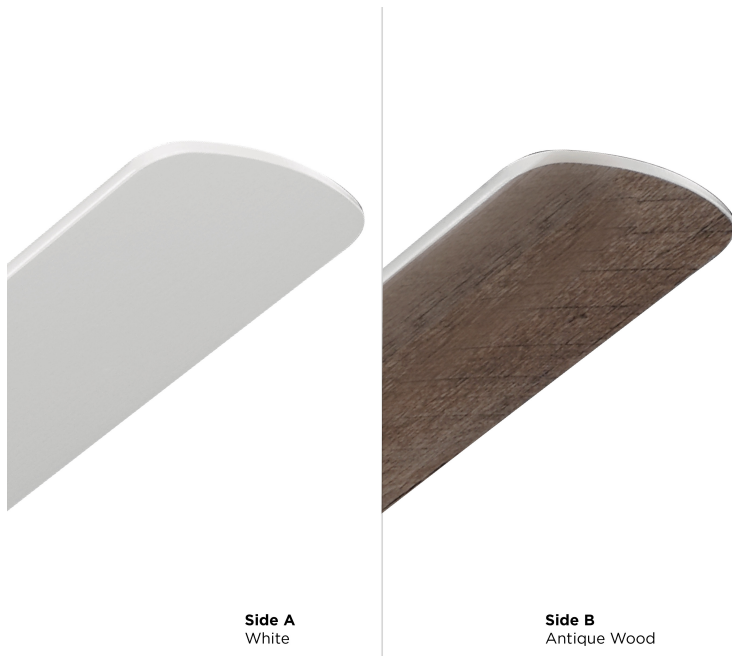

ENERGYGUIDE	
Estimated Yearly Energy Cost \$10	Airflow 3,328 <small>Cubic Feet Per Minute</small>
<div style="border: 1px solid black; width: 100%; height: 15px; position: relative;"> \$3 \$34 </div> <small>Cost Range of Similar Models (19" – 84")</small>	<small>• The higher the airflow, the more air the fan will move</small> <small>• Airflow Efficiency: 93 Cubic Feet Per Minute Per Watt</small>
<small>• Based on 12 cents per kWh and 6.4 hours use per day</small> <small>• Your cost depends on rates and use</small> <small>• Energy Use: 36 Watts</small>	
<small>All estimates based on typical use, excluding lights</small>	
<small>ftc.gov/energy</small>	

REVERSIBLE FAN BLADE FINISHES
