

# Paso

Ceiling downrod Mounted • Damp Location Listed **PROGRESS LED**

### Description:

Paso Collection 60-in Three-Blade Vintage Brass with Matte White Blades Luxe Industrial Ceiling Fan with 3 Speed Remote Control with Wall Bracket and Battery included


### Specifications:

- Canopy covers a standard 4" recessed outlet box

### Performance:

Input Voltage	120 VAC
Warranty	Limited Lifetime Warranty
Labels	UL Damp Location Listed DC motor

# P250109-163

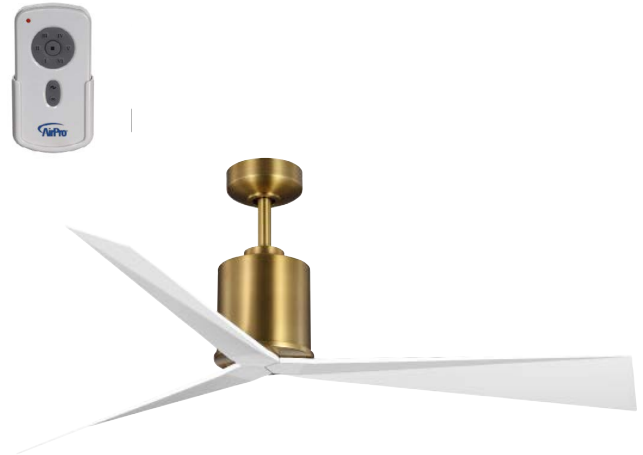


### Dimensions:

Diameter: 60 in  
 Height: 16-1/2 in

## ENERGYGUIDE

**Estimated  
Yearly Energy Cost**

# \$6



Cost Range of Similar Models (19" – 84")

- Based on 12 cents per kWh and 6.4 hours use per day
- **Your cost depends on rates and use**
- Energy Use: 21 Watts

**Airflow**

# 3,659

Cubic Feet Per Minute

- The higher the airflow, the more air the fan will move
- Airflow Efficiency: 174 Cubic Feet Per Minute Per Watt

All estimates based on typical use, excluding lights ftc.gov/energy