

WHIRL

 Ceiling mounted • Damp location listed **PROGRESS LED**

Description:

Refresh your indoor or covered outdoor living spaces with the crisp, clean style of the 60" Whirl fan. The stylish design comes in Antique Nickel, Antique Bronze and Forged Black finish options. The five-blade fan features an all weather damp location rating (ABS) to accommodate a variety of settings throughout the home. White opal glass shade with a 17W LED light source offers a warm 3000K-color temperature, energy savings and maintenance benefits for the home. Whirl features a dual mount system and a three-speed pull chain fan switch, as well as an on/off pull chain switch to operate the light. Can be used to comply with California Title 20.

Specifications:

- Forged Black (-80) (Painted)
- Steel construction
- White opal glass Diffuser
- Refresh your indoor or covered outdoor living spaces with the crisp, clean style of the 60" Whirl fan
- The five-blade fan features an all weather damp location rating (ABS blades) to accommodate a variety of settings throughout the home
- White opal glass shade with a 17W dimmable LED light source offers a warm 3000K-color temperature, 90 CRI and 1400 lumens
- Whirl features a dual mount system and a three-speed pull chain fan switch, as well as an on/off pull chain switch to operate the light.
- Reversible motor for year round comfort allows you to choose either a down drafts (summer) or an up draft (winter)
- Add a P2630-30 wall control or P2614-30 remote control for added convenience
- As a general rule of thumb, lighting experts suggest this fan is ideal in a room size that is larger than 400-square feet
- A 3/4" x 6" downrod is included. Longer accessory downrods can be ordered separately
- Can be used to comply with California Title 20.
- High Speed Energy Information: Airflow- 6549 cfm, Energy consumption- 70 watts (excluding lights), Airflow efficiency- 94 cfm/watt
- Canopy covers a standard 4" octagonal recessed outlet box
- Mounting strap for outlet box included
- 80" of wire supplied
- Toasted Oak blades, plastic construction
- Chrome pull chain with Walnut fob
- 12 degree blade pitch
- Meets California Title 24 JA8-2016

Performance:

Number of Modules	1
Input Power	18w
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW	1386/77 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	46,000 (L70/TM-21)
EMI/RFI	Title 20
Min. Start Temp	-10 °C
Max. Operating Temp	40 °C
Warranty	Limited Lifetime warranty
Labels	UL Damp location listed
	Meets California Title 24 JA8-2016

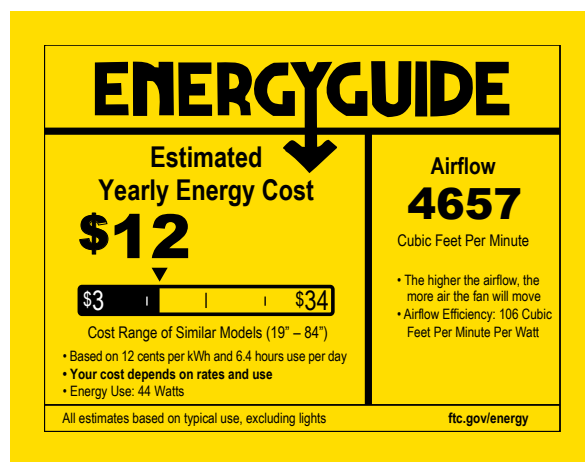
 For more information visit our website: www.progresslighting.com

P2574-8030K

Images:



Dimensions:

 Diameter: 60"
 Height: 15-7/8"


P2574-8030K

Dimming Notes:

P2574 is designed to be compatible with many controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls

Lutron - NTEVL-300

Lutron - DVELV-300P

Lutron - Caseta Wireless

Leviton – 6672

Leviton – 6674

Lutron - AYCL-153P

Lutron - AYLV-600P

Lutron - MAELV-601

Leviton - AWRMG-EAW

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation. Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.