



DATE: \_\_\_\_\_ TYPE: \_\_\_\_\_

NAME: \_\_\_\_\_

PROJECT: \_\_\_\_\_

Solid state

# P2582-0930K

## Gust

This five-blade 54" Gust ceiling fan features a white opal shade. A remote with batteries is included. Gust has a dual mount system to offer greater flexibility when installing. The 17W dimmable, 3000K LED module provides energy- and cost-savings benefits to the homeowner.

- 54" Gust indoor ceiling fan features five blades and an LED light source, offering both form and function with energy- and cost-savings benefits
- The light kit contains a white opal shade and contains a 17W dimmable 3000K LED module with 90CRI and 1400 lumens
- Features Graphite blades and a Graphite finish
- A hand held remote control with fan speed control and full range light dimming is included and comes with a convenient wall bracket for storage
- Remote control may be replaced by a P2630-30 wall control
- The five-blade Gust fan features a dual mount system to offer greater flexibility when installing
- The fan can be installed on a flat or sloped ceiling
- Indoor ceiling fan ideal for use in great rooms, living rooms, bedrooms and bonus rooms
- Ideal for Contemporary interiors
- Reversible motor for year round comfort allows you to choose either a down draft (summer) or an up draft (winter)
- As a general rule of thumb, lighting experts suggest this fan is ideal in a room size that ranges from 226- to 400-square feet
- UL dry location listed for indoor use
- A 3/4" x 6" downrod is included. Longer accessory downrods can be ordered separately
- High Speed Energy Information: Airflow— 5242 cfm, Energy consumption— 65 watts (excluding lights), Airflow efficiency— 80 cfm/watt
- Limited Lifetime Warranty

**Category:** Ceiling Fans


**Finish:** Brushed Nickel (Plated)

**Construction:** Steel construction

**Glass:** Diffuser



**Diameter: 54"**  
**Height: 16"**

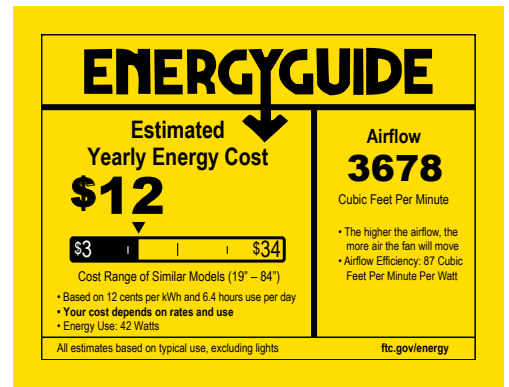

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Ceiling mounted  Mounting strap for outlet box included  Canopy covers a standard 4" octagonal recessed outlet box  5.875" W., 2.25" ht., 5.875" depth	Pre-wired  80" of wire supplied  120 V	Quantity:  One 18w max. LED(included)  LED base	UL Dry location listed  Limited Lifetime warranty  Meets California Title 24 JA8-2016