

Phase 1.1 LED

Wall Mounted • Damp Location Listed **PROGRESS LED**

Description:

Phase 1.1 LED Collection 36" LED Linear Bath & Vanity

Specifications:

- White Acrylic Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Back plate covers a standard 4" recessed outlet box: 7.0625 in W., 4.75 in ht., 0.375 in depth
- Mounting plate for outlet box included
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

Performance:

Number of Modules	1
Input Power	33 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	2,600/78 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Max. Operating Temp	30°C
Warranty	5-year Limited Warranty
Labels	cETLus Damp Location Listed
	Meets California Title 24 JA8-2016


P300224-009-30



Dimensions:

Width: 36 in
 Depth: 4 in
 Height: 4-3/4 in
 H/CTR: 2-3/8 in (mounted horizontal)

White Acrylic Diffuser
 Width: 35-1/8 in
 Height: 2-5/8 in

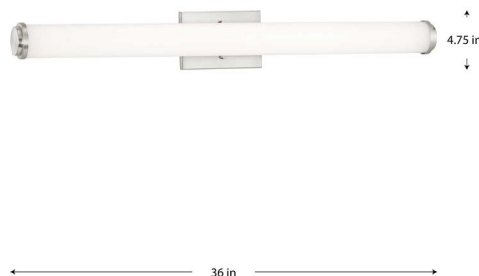

P300224-009-30

Dimming Notes:

P300224-009-30 is designed to be compatible with many Triac/Forward Phase ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Lutron_Nova T NTELV-300

Lutron_Diva DVELV-300P

Lutron_Diva DVCL-253P

Lutron_Caseta

IDevices_IDEV0009

Lutron_Ariadni AYCL-153P

Lutron_Ariadni AYLV-600P

Leviton_AWRMG-EAW

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.