

Pearl LED

Wall Mounted • Damp Location Listed **PROGRESS LED**

Description:

Pearl LED Collection 4-Light Matte Black Opal Glass LED Modern Bath Vanity Light


Specifications:

- Opal Glass Globe
- Dimmable to 10% brightness (See Dimming Notes)
- Canopy covers a standard 4" recessed outlet box: 23.875 in W., 5 in ht., 1.25 in depth
- Mounting backplate for outlet box included
- 6 in of wire supplied

Performance:

Number of Modules	4
Input Power	24 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	1,692/71 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cETLus Damp Location Listed Meets California Title 24 JA8-2019

P300313-031-30

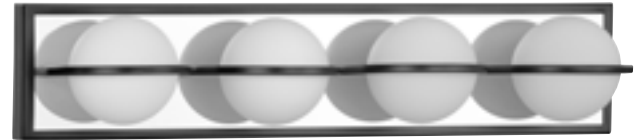

Dimensions:

Length: 23-7/8 in
Extends: 5-1/2 in
Height: 5 in
H/CTR: 2-1/2 (glass facing up)

Opal Glass Globe
Width: 4 in
Height: 4 in

P300313-031-30

Dimming Notes:

P300313-031-30 is designed to be compatible with many ELV controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Lutron_DVELV-300P

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.