

Phase 4 LED

Wall Mounted • Damp Location Listed **PROGRESS LED**

Description:

Phase 4 Collection 24 in. Brushed Nickel Medium Modern Integrated 3CCT Integrated LED Linear Vanity Light

Specifications:

- Diffused Plastic Flat Square/Rectangular
- Dimmable to 10% brightness (See Dimming Notes)
- Canopy covers a standard 4" recessed outlet box: 4.5 in W., 4.5 in ht., 1.26 in depth
- Mounting backplate for outlet box included
- 10 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

Performance:


Number of Modules	1
Input Power	18 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	1,231/68 (LM-79)
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cCSAus Damp Location Listed
	Meets California Title 24 JA8-2016

P300404-009-CS



Dimensions:

Width: 24 in
Extends: 2 in
Height: 4-3/4 in

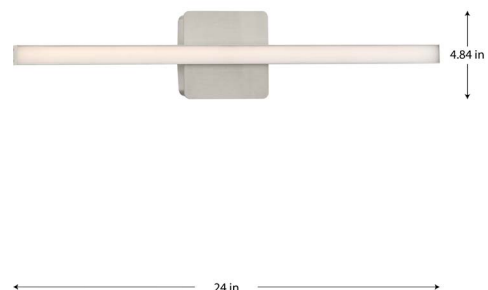

Dimming Notes:

P300404-009-CS is designed to be compatible with many ELV/Reverse Phase Triac/Forward Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Eaton SAL06P

Leviton IPI06-1LZ

Leviton 6672

Leviton 6674

Lutron NTEVL-300

Lutron DVELV-300P

Lutron DVCL-253P

Lutron Caseta Wireless

Idevices IDEV009

Lutron AYCL-153P

Lutron SCL-153P

Lutron TGCL-153-PH-WH

Lutron MACL-153M

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.

P300404-009-CS