

One-Light LED Flush Mount

 Ceiling mounted • Damp location listed **PROGRESS LED**


P350017-020-30

Description:

One-light 9-1/2 inch Square LED Flush Mount featuring a square Random Swirl glass bowl in an Antique Bronze finish. Fixtures are dimmable to 10 percent with Triac or ELV dimmers. 3000K and 90CRI.

Specifications:

- Antique Bronze (-020) (painted)
- Steel Construction
- Random Swirl glass diffuser
- LED Module is replaceable (part # 93074038)
- 3000k color temperature, 90+ CRI
- 1452 lumens 83 lumens/watt (source).
- Dimmable to 10% brightness (See Dimming Notes)
- Unit covers a standard 4" octagonal recessed outlet box
- Mounting strap for outlet box included
- 6" of wire supplied
- ENERGY STAR® qualified
- Meets California Title 24 JA8-2016

Performance:

Number of Modules	1
Input Power	17w
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Source)	1452/83 (LM-82)
Lumens/LPW (Delivered)	1140/65.5 (LM-79)
CCT	3000 K
CRI	90+
Life (hours)	60,000 (L70/TM-21)
FCC	Meets FCC Title 47, Part 15 Class B
Min. Start Temp	-30 °C
Max. Operating Temp	30 °C
Warranty	5 year warranty
Labels	cCSAus Damp location listed ENERGY STAR® qualified Meets California Title 24 JA8-2016

Images:



Dimensions:

Square: 9-1/2"
Height: 4-1/2"

Glass
Width: 9-1/2"
Length: 9-1/2"
Height: 425"

Photometrics:

P350017-020-30

ELECTRICAL DATA	P350017-020-30
Input Voltage	120 V
Input Frequency	60 Hz
Input Current	0.142 A
Input Power	17
Power Factor	Greater than 0.90
THD	<20%
FCC	Meets FCC Title 47, Part 15 Class B
Operating Temperature	-30 °C to 30 °C
Dimming	Yes*

*See Dimming Notes for more information

P350017-020-30


LED Light Engine: 3000 K 90+
 System Wattage: 17
 Fixture delivered lumens: 1140
 Fixture Efficacy: 65.5
 Spacing Criteria: 1.3

CANDELA DISTRIBUTION

DEG	CANDELA	LUMENS
0	303	
5	302	29
15	293	83
25	275	127
35	248	155
45	210	162
55	166	148
65	121	120
75	82	87
85	53	58
90	42	
95	34	37
105	23	25
115	18	18
125	15	14
135	14	11
145	12	7
155	10	4
165	6	2
175	4	0
180	3	

ZONAL LUMEN SUMMARY

ZONE	LUMENS	%FIXT
0-30	238	21.9
0-40	393	36.1
0-60	703	64.7
0-90	969	89.1
90-120	80	7.4
90-130	94	8.6
90-150	112	10.3
90-180	119	10.9
0-180	1087	100.0

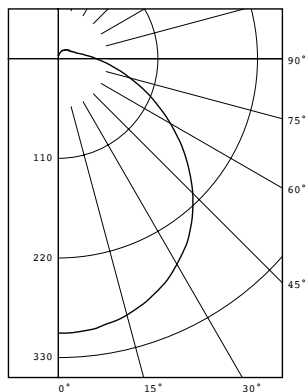

Test 16.02780 Test Date 10/22/16

P350017-020-30

Dimming Notes:

P350017 is designed to be compatible with many NEMA SSL 7a Phase Cut (forward phase) dimmers as well as many ELV (reverse phase) controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls

Lutron Diva DVELV-300P

Lutron Nova T NTELV-300

Lutron Caseta

Lutron Ariadni AY-600P

Leviton Illumatech IPI06-1LZ

Lutron Lumea LG-603PG

Leviton SureSlide 6672

Leviton SureSlide 6674

Lutron Ariadni AYCL-153P

Lutron Skylark Contour CTCL-153P

Lutron Diva DVCL-153P

Pass & Seymour Harmony DCL453PTCCCV6

Lutron Toggler TGCL-153P

Lutron Maestro MACL-153M

Lutron Ariadni AYL-600P

Lutron Maestro MA-600

Lutron NOVA T NTLV-600

lutron Maestro MAELV-600

Lutron spacer/system SPSELV-600

Lutron Renoir II AWRMG-EAW

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation. Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.