

One-Light LED Flush Mount

Ceiling mounted • Damp location listed



P350089-078-30

Description:

Finesse LED flush mount fixtures take on a new perspective with an open cage design. The beautifully graphic frame, in Vintage Gold, closes to create a circular pattern. The form casts a pleasing illumination and complements popular wire designs found in other home accents and furniture. Ideal for 8 to 9 foot ceilings in spaces that showcase Mid-Century or Modern styling.


Specifications:

- Vintage Gold (-078) (painted)
- Steel construction
- Etched Opal Glass Bowl
- LED Module is replaceable (part # 93074038)
- Finesse takes on a new perspective in open cage design
- Finesse features a beautifully graphic frame, while complementing popular wire designs found in other home accents
- The unique design closes to create a circular pattern
- 1-light 17-watt LED flush mount fixture
- Measures 15" diameter x 4 1/2" H
- Warm white 3000K lighting color
- 731 lumens, 41.3 lumens per watt (delivered)
- 90+CRI
- Ideal for low ceilings or small foyer spaces that showcase Mid-Century, Bohemian or Modern styling
- Close-to-ceiling lights are natural choices for closets, hallways, and small rooms
- Replaceable light engine is California JA8 certified
- California Title 24 compliant
- Damp location listed
- Dimmable to 10% brightness (See Dimming Notes)
- Canopy covers a standard 4" octagonal recessed outlet box
- Mounting strap for outlet box included
- 6" of wire supplied
- ENERGY STAR® qualified
- Meets California Title 24 JA8-2016

Performance:

Number of Modules	1
Input Power	17w
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Source)	1452/83 (LM-82)
Lumens/LPW (Delivered)	731/41.3 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	60,000 (L70/TM-21)
FCC	Meets FCC Title 47, Part 15 Class B
Min. Start Temp	-30 °C
Warranty	5 year limited warranty
Labels	cCSAus Damp location listed ENERGY STAR® qualified Meets California Title 24 JA8-2016

Images:

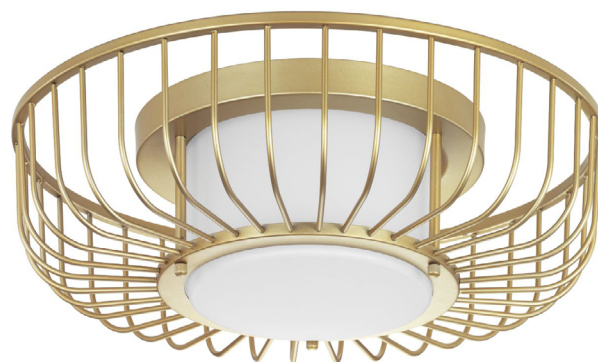

Dimensions:

 Diameter: 15"
 Height: 4-1/2"

 Glass
 Width: 6-1/2"
 Length: 6-1/2"
 Height: 3-13/16"

P350089-078-30

Dimming Notes:

P350089 is designed to be compatible with many Triac/Forward Phase or ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls

Lutron Diva DVELV-300P

Lutron Nova T NTELV-300

Lutron Caseta

Lutron Ariadni AY-600P

Leviton Illumatech IPI06-1LZ

Lutron Lumea LG-603PG

Leviton SureSlide 6672

Leviton SureSlide 6674

Lutron Ariadni AYCL-153P

Lutron Skylark Contour CTCL-153P

Lutron Diva DVCL-153P

Pass & Seymour Harmony DCL453PTCCCV6

Lutron Toggler TGCL-153P

Lutron Maestro MACL-153M

Lutron Ariadni AYL-600P

Lutron Maestro MA-600

Lutron NOVA T NTLV-600

Lutron Maestro MAELV-600

Lutron spacer/system SPSELV-600

Lutron Renoir II AWRMG-EAW

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation. Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.