


Project: \_\_\_\_\_  
 Fixture Type: \_\_\_\_\_  
 Location: \_\_\_\_\_  
 Contact: \_\_\_\_\_

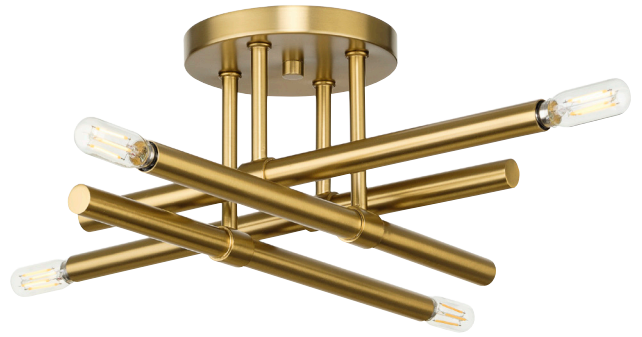

**P350257-191**  
**Arya**

Arya Collection Four-Light Brushed Gold Luxe 20" Semi-Flush Mount Light

**Category:** Close-to-Ceiling  
**Finish:** Brushed Gold (Plated)  
**Construction:** Steel Construction

Width: 20-1/8 in (does not include bulb)  
 Height: 4.5 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Semi-Flush	6 inches of wire supplied	(4) Candelabra Base (E12) Socket	cCSAus Damp Location Listed
1/8 IP mounting plate for outlet box included	120 VAC	Lamp Type B10	1-year Limited Warranty
Canopy covers a standard 4" recessed outlet box: 6" W., 0.81" ht., 6" depth		Incandescent: 60-watt MAX per socket LED: 12.5-watt MAX per socket Fully dimmable with dimmable bulbs	