

# Abide LED

Ceiling Flush Mounted • Damp Location Listed

## Description:

One-Light LED Flush Mount

## Specifications:

- Matte Black (Painted)
- Steel Housing
- White PMMA Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Fixture covers a standard 4" recessed outlet box
- 6 in of wire supplied

## Performance:

Input Power	16 W
Input Voltage	120 VAC
Input Frequency	60 Hz
Lumens/LPW (Delivered)	1,062/65.6 (LM-79)
CCT	2700 K
	3000 K
	3500 K
	4000 K
	5000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cCSAus Damp Location Listed
	Meets California Title 24 JA8-2022


# P350274-31M-CS



## Dimensions:

Diameter: 10-3/16 in  
 Height: 2-3/4 in

White PMMA Diffuser  
 Diameter: 9-1/4 in  
 Height: 2-1/2 in

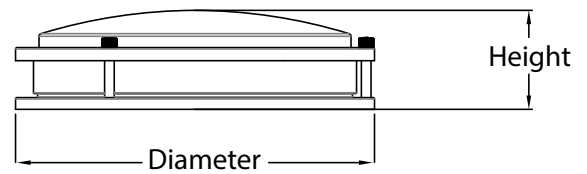

**Photometrics:**

<b>ELECTRICAL DATA</b>	<b>P350274-31M-CS</b>
Input Voltage	120 VAC
Input Frequency	60 Hz
THD	<25%
EMI/RFI	FCC Title 47, Part 15, Class B
Operating Temperature	-30 °C to 30 °C
Dimming	Yes*
Over-voltage, over-current, short-circuit protected	
*See Dimming Notes for more information	

# P350274-31M-CS

# P350274-31M-CS

**Dimming Notes:**

P350274-31M-CS is designed to be compatible with many ELV/Reverse Phase Triac/Forward Phase controls.

The following is a partial list of known compatible dimmer controls.

**Dimming Controls:**

- Lutron NTELV-300
- Lutron DVELV-300P
- Lutron DVCL-253P
- Lutron Caséta
- Leviton 6672
- Leviton 6674
- Lutron AYCL-153P
- Lutron SCL-153P
- Lutron TGCL-153PH
- Lutron MACL-153M
- Eaton - AAL06

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation. Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements. Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.