

Cloud LED

Ceiling Flush Mounted • Damp Location Listed

Description:

One-Light LED Flush Mount

Specifications:

- White (Painted)
- Steel Housing
- White PMMA Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Fixture covers a standard 4" recessed outlet box
- 6 in of wire supplied

Performance:

Input Power	15.5 W
Input Voltage	120 VAC
Input Frequency	60 Hz
Lumens/LPW (Delivered)	1,264/80.6 (LM-79)
CCT	2700 K
	3000 K
	3500 K
	4000 K
	5000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cCSAus Damp Location Listed
	Meets California Title 24 JA8-2022


P350278-030-CS



Dimensions:

Diameter: 11-1/8 in
 Height: 3-1/2 in

White PMMA Diffuser
 Diameter: 11-1/8 in
 Height: 3-1/2 in

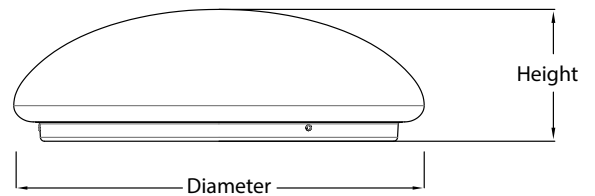

Photometrics:

ELECTRICAL DATA	P350278-030-CS
Input Voltage	120 VAC
Input Frequency	60 Hz
THD	<25%
EMI/RFI	FCC Title 47, Part 15, Class B
Operating Temperature	-30 °C to 30 °C
Dimming	Yes*
Over-voltage, over-current, short-circuit protected	
*See Dimming Notes for more information	

P350278-030-CS

P350278-030-CS

Dimming Notes:

P350278-030-CS is designed to be compatible with many ELV/Reverse Phase Triac/Forward Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Lutron NTELV-300

Lutron DVELV-300P

Lutron DVCL-253P

Lutron Caséta

Leviton 6672

Leviton 6674

Lutron AYCL-153P

Lutron SCL-153P

Lutron TGCL-153PH

Lutron MACL-153M

Eaton AAI06

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation. Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements. Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.