


DATE: \_\_\_\_\_ TYPE: \_\_\_\_\_

NAME: \_\_\_\_\_

PROJECT: \_\_\_\_\_

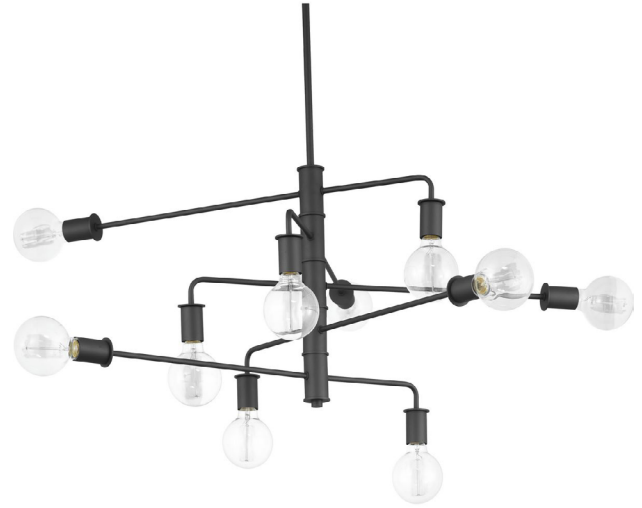

# P400144-143

## Calder

Calder collection of fixtures celebrates the elegance of movement with a graceful articulating center column. Pivoting arms provide a nearly endless array of configurations to complement the asymmetric design. Larger scale design is suitable for open floor plans, great rooms or anywhere a dramatic focal piece is needed to make a bold statement. The minimal form provides a perfect showcase for vintage or globe style light bulbs.

**Diameter: 38-1/2"**  
**Height: 18-3/8"**  
**Overall Ht. W/Stem: 76-1/2"**

- Calder celebrates the intersection of mechanical forms and movement
- Great scale, architectural details and clean lines are found throughout Calder's design
- Uses 10, 60-watt max. medium base bulbs including LED equivalent (sold separately)
- Calder is a perfect showcase for vintage bulbs, including T10, G30 or A lamp styles
- Shown with Progress Lighting's P860028-001 lamp
- Influenced by the working parts of powerful machines
- Ideal for Mid Century, Modern or Bohemian design styles
- Each horizontal arm intersects through a center column
- Part of Progress Lighting's Design Series - designer-influenced collections that make a statement within the home
- Ideal for open floor plans to define living spaces within the home
- Adjustable arms pivot for easy customization - offering both form and function for interior design schemes
- Measures 38 1/2 diameter x 19 3/8" H (not including bulbs)
- Ceiling stem hung from round canopy
- Dry location listed

**Category:** Chandeliers

**Finish:** Graphite (painted)

**Construction:** Steel construction

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Ceiling Stem Hung mounted Mounting strap for outlet box included One 6", four 12" lengths of stem included Canopy covers a standard 4" octagonal recessed outlet box 5" W., 1.125" ht., 5" depth	Pre-wired 10 feet of wire supplied 120 V	Quantity: Ten 60w max. medium base E26 base Porcelain sockets	cULus Dry location listed 1-year limited warranty