

Project: \_\_\_\_\_

Fixture Type: \_\_\_\_\_


Location: \_\_\_\_\_

Contact: \_\_\_\_\_

**P400399-31M**  
**Gilliam**

Twenty-Light Chandelier

**Category:** Chandelier  
**Finish:** Matte Black (Painted)  
**Construction:** Steel Construction

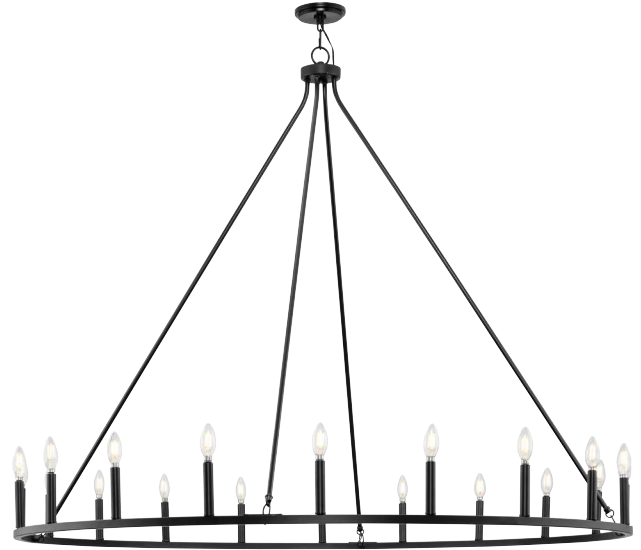

Diameter: 61-1/8 in  
Height: 48-1/8 in  
Overall Ht. W/Chain: 111 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Ceiling Chain	15 feet of wire supplied	(20) Candelabra Base (E12) Socket	cULus Dry Location Listed
1/4 IP mounting plate for outlet box included	120 VAC	Lamp Type B10	1-year Limited Warranty
5 feet of 9 Gauge chain supplied with quick link		Incandescent: 60-watt MAX per socket LED: 12.5-watt MAX per socket	
Canopy covers a standard 4" recessed outlet box: 5" W., 0.81" ht., 5" depth		Dimmable to 10% brightness (See Dimming Notes)	