

Project: _____

Fixture Type: _____

Location: _____


Contact: _____

P500232-031 Cumberland

Experience the sense of shelter, warmth, and protection offered by the mountain modern glow of this foyer light. Let wandering eyes hungry for a satisfying lighting experience satiate their appetites as their gaze feasts upon the artistic yet playful tic-tac-toe pattern intricately weaved into the matte black frame. Signature seeded glass panes fosters a gazing window design that grants the light fixture a rustic, modern cabin vibe.

- Signature seeded glass panes fosters a gazing window design that grants the light fixture a rustic, modern cabin vibe.
- Let wandering eyes hungry for a satisfying lighting experience satiate their appetites as their gaze feasts upon the artistic yet playful tic-tac-toe pattern intricately weaved into the matte black frame.
- Experience the sense of shelter, warmth, and protection offered by the mountain modern glow of this foyer light.
- Ideal for any foyer, dining room, or kitchen.
- Measures 16-7/8-inch width by 27-5/8-inch height.
- Uses eight candelabra base bulbs that are sold separately (60w max - LED or incandescent).
- Able to be fully dimmable with dimmable bulbs.
- Includes installation instructions and mounting hardware.
- Progress Lighting products are designed for exceptional quality, reliability, and functionality.

Category: Hall & Foyer
Finish: Matte Black (Painted)
Construction: Steel Construction
Glass/Shade: Clear seeded glass Round Panel

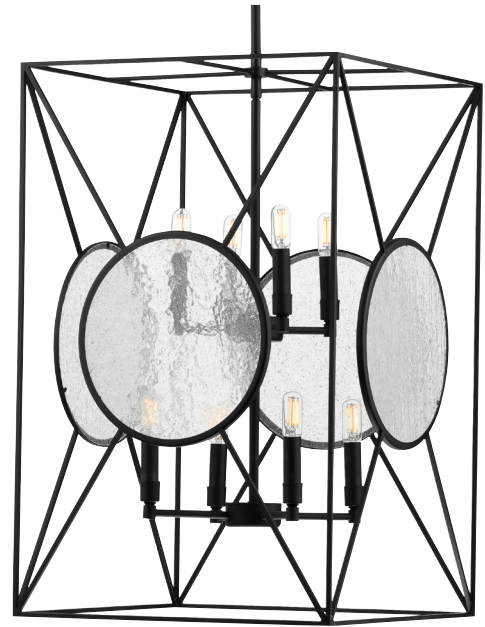

Square: 16-7/8 in
Height: 27-5/8 in
Overall Ht. W/Chain: 94 in

Clear seeded glass Round Panel
Width: 10-1/16 in
Height: 10-1/16 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Ceiling stem hung with 6 links of chain mounted	Prewired	Quantity:	CETLus Dry Location Listed
1/8 IP mounting plate for outlet box included	15 feet of wire supplied	Eight 60 W max. Candelabra Base or LED equivalent	1-year Limited Warranty
Six links of 9 gauge chain supplied	120 V	E12 base Phenolic sockets	
One 6", four 12" lengths of stem included			
Canopy covers a standard 4" recessed outlet box: 5.125" W., 0.75" ht., 5.125" depth			