



DATE: \_\_\_\_\_ TYPE: \_\_\_\_\_

NAME: \_\_\_\_\_

PROJECT: \_\_\_\_\_

Incandescent

# P5512-16

## Cast Aluminum


Two light wall fixture with threaded opal glass shades that screw onto fitter. Vapor-proof gaskets and porcelain sockets. Mounts horizontally or vertically.

Category: Outdoor

Finish: Satin Aluminum (powdercoat)

Construction: Cast aluminum construction

Glass: White opal glass cylindrical diffuser

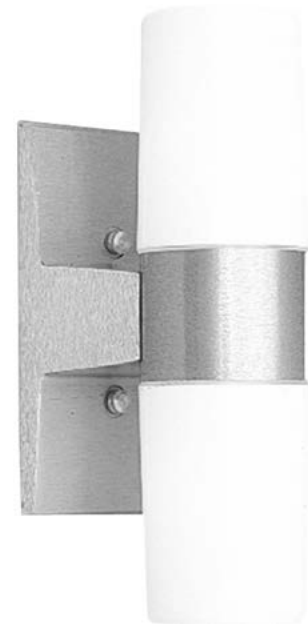

Width: 4-1/2"

Height: 13"

Depth: 6"

H/CTR: 6-1/2"

Glass: 3-3/4" dia.

Height: 6-5/16"

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Wall horizontal or vertical mounted  Mounting strap for outlet box included  Back plate covers a standard 4" hexagonal recessed outlet box	Pre-wired  6" of wire supplied  120V	Quantity: 2 100W Medium Base  Medium porcelain sockets	UL-CUL Wet location listed  1 year warranty  Companion fixtures are available