

## Z-1010 LED

Wall Mounted • Wet Location Listed **PROGRESS LED**

### Description:

Z-1010 Collection One-Light LED Wall Lantern


### Specifications:

- Clear Seeded Glass Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Unit covers a standard 4" recessed outlet box: 0.0625 in W., 4.1875 in ht., 4 in depth
- Mounting strap for outlet box included
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant
- Dark Sky compliant

### Performance:


Number of Modules	1
Input Power	9 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Source)	624/66 (LM-82)
Lumens/LPW (Delivered)	279/29.7 (LM-79)
CCT	3000 K
CRI	90+ CRI
Life (hours)	60000 (L70/TM-21)
EMI/RFI	Meets FCC Title 47, Part 15 Class B
Max. Operating Temp	30 °C
Warranty	5-year Limited Warranty
Labels	cCSAus Wet Location Listed
	Meets California Title 24 JA8-2016

## P560029-031-30

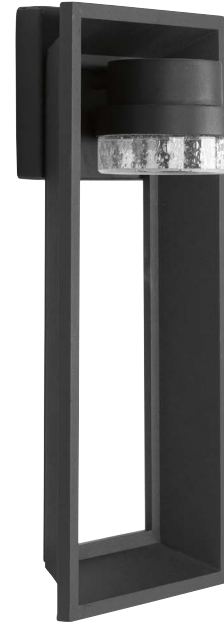

### Dimensions:

Width: 7-1/2 in  
 Depth: 4-3/4 in  
 Height: 16 in  
 H/CTR: 4-1/4 in

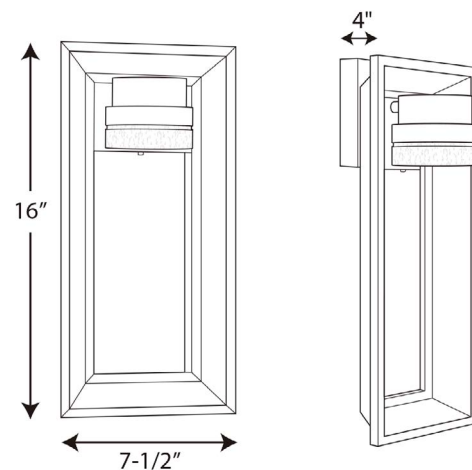

# P560029-031-30

## Dimming Notes:

---

P560029-031-30 is designed to be compatible with many Triac/Forward Phase ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

## Dimming Controls:

---

Lutron\_Diva DVELV-300P

Lutron\_Nova T NTELV-300

Lutron\_Caseta

Lutron\_Ariadni AY-600P

Leviton\_Illumatech IPI06-1LZ

Leviton\_SureSlide 6672

Lutron\_Skylark Contour CTCL-153P

Lutron\_Diva DVCL-153P

Lutron\_Toggler TGCL-153P

Lutron\_Maestro MACL-153M

Lutron\_Ariadni AYLV-600P

Lutron\_Nova T NTLV-600

Lutron\_Maestro MAELV-600

Lutron\_spacer/system SPSELV-600

Leviton\_Renoir II AWRMG-EAW

Lutron\_Nova N-600

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.