

Z-1070 LED

Wall vertical only Mounted • Wet Location Listed **PROGRESS LED**

Description:

Z-1070 LED Collection Black One-Light Small LED Outdoor Sconce

Specifications:

- White Acrylic Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Canopy covers a standard 4" recessed outlet box: 4.75 in W., 10.25 in Ht., 0.75 in depth
- Mounting backplate for outlet box included
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

Performance:

Number of Modules	1
Input Power	11 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	528/48 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	54000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cCSAus Wet Location Listed Meets California Title 24 JA8-2019


P560208-031-30



Dimensions:

Width: 6 in
Depth: 3-3/4 in
Height: 12-9/16 in
H/CTR: 6-1/4 in

White Acrylic Diffuser
Width: 4-7/16 in
Height: 12 in

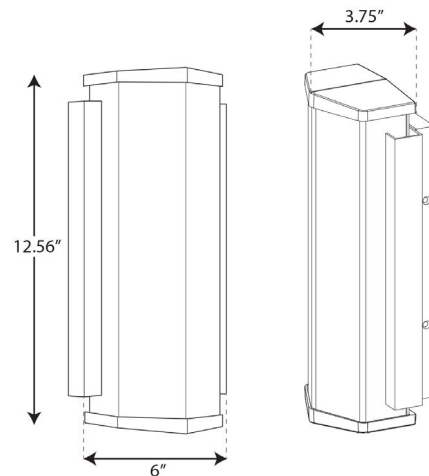

P560208-031-30

Dimming Notes:

P560208-031-30 is designed to be compatible with many Triac/Forward Phase ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Leviton_IPI06-1LZ

Leviton_SureSlide 6674

Lutron_Nova T VTELV-300

Lutron_Diva DVELV-300P

Lutron_Ariadni AYCL-153P

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.