

## Z-2040 LED

Wall Mounted • Wet Location Listed **PROGRESS LED**

### Description:

One-light LED Wall Lantern


### Specifications:

- Diffused Acrylic Rectangular
- Canopy covers a standard 4" recessed outlet box: 4.5 in W., 4.5 in ht., 0.314 in depth
- Mounting backplate for outlet box included
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

### Performance:

|                        |                            |
|------------------------|----------------------------|
| Input Power            | 4 W                        |
| Input Voltage          | 120 VAC                    |
| Lumens/LPW (Delivered) | 181/54.8 (LM-79)           |
| CCT                    | 3000 K                     |
|                        | 3500 K                     |
|                        | 4000 K                     |
| CRI                    | 90 CRI                     |
| Life (hours)           | 50000 (L70/TM-21)          |
| Warranty               | 5-year Limited Warranty    |
| Labels                 | cETLus Wet Location Listed |
| THD                    | <20%                       |
| Operating Temperature  | -30 °C to 30               |
| Dimming                | No                         |

## P560366-31M-CS

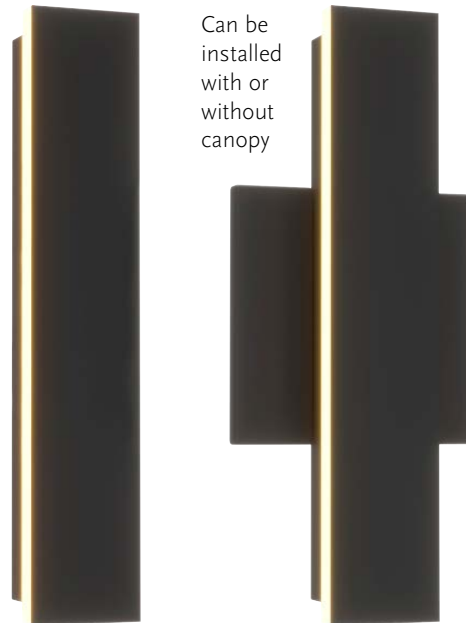

Can be installed with or without canopy

### Dimensions:

Width: 2 in (4-1/2 in with canopy)  
Depth: 1-11/16 in  
Height: 12 in

Diffused Acrylic Rectangular  
Length: 2 in  
Width: 0-7/16 in  
Height: 12 in



Use your mobile phone camera to scan the QR code to open a link to a helpful installation video.

<https://www.youtube.com/watch?v=7lFwuRbTISw&t=14s>