

## East Haven LED

Wall Mounted • Wet Location Listed **PROGRESS LED**

### Description:

East Haven Collection Small LED Wall Lantern

### Specifications:

- Clear Seeded Glass Shade
- White Acrylic Diffuser
- Dimmable to 10% brightness (See Dimming Notes)
- Back plate covers a standard 4" recessed outlet box: 4.3125 in W., 6.0625 in ht., 4.3125 in depth
- Mounting strap for outlet box included
- 6 in of wire supplied
- Dark Sky compliant

### Performance:

Number of Modules	1
Input Power	9 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Source)	623/69.2 (LM-82)
Lumens/LPW (Delivered)	310/41.9 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	60000 (L70/TM-21)
EMI/RFI	Meets FCC Title 47, Part 15 Class B
Max. Operating Temp	30 °C
Warranty	5-year Limited Warranty
Labels	cCSAus Wet Location Listed

## P6077-2030K9




### Dimensions:

Width: 5-3/4 in  
 Height: 7-7/8 in  
 Depth: 7-1/2 in  
 H/CTR: 4-3/4 in

Clear Seeded Glass Shade  
 Length: 4.3125 in  
 Width: 4-5/16 in  
 Height: 5 in

White Acrylic Diffuser  
 Width: 2-7/8 in  
 Height: 0-13/16 in

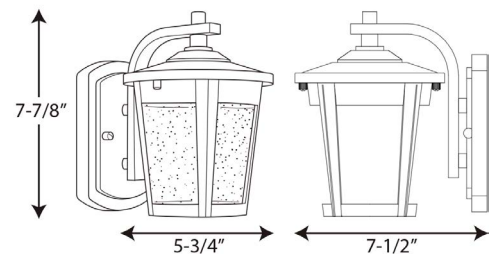

# P6077-2030K9

## Dimming Notes:

---

P6077-2030K9 is designed to be compatible with many ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

## Dimming Controls:

---

Lutron\_Nova T NTELV-300

Lutron\_Vierti VTELV-600

Lutron\_Maestro MAELV-600

Lutron\_spacer/system SPSELV-600

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.