



Type	_____	
	-16	-31
P6816	<input type="checkbox"/>	
P6817	<input type="checkbox"/>	<input type="checkbox"/>
P6818	<input type="checkbox"/>	
P6819	<input type="checkbox"/>	

Catalog No.	Finish		Faceplate	Lamping	Dimensions (Inches)		
	Aluminum	Black			A	B	C
P6816	-16		White Glass	1-25w A19	7-3/4	5	3-1/2
P6817	-16	-31	Louver/Glass	1-25w A19	7-3/4	5	3-1/2
P6818	-16		White Glass	1-75w A19	8-3/4	5-7/8	3-1/2
P6819	-16		Louver/Glass	1-75w A19	8-3/4	5-7/8	3-1/2

Wall Opening = 4-1/4 x 7  
Wall Opening = 5-1/8 x 8

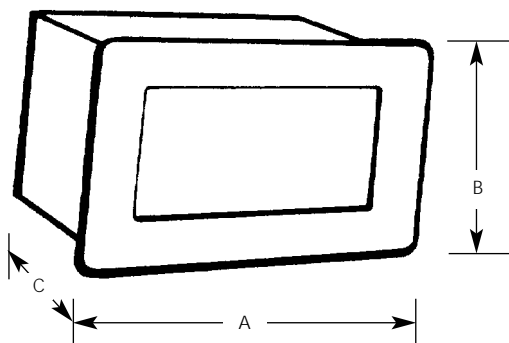

**P6816 & P6818 (White Glass)**

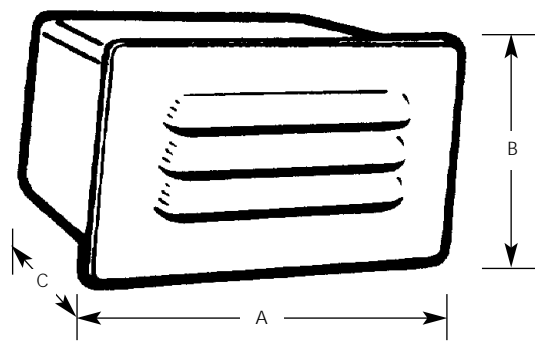

**P6817 & P6819 (Louver)**

**Specifications:**

Faceplate Assembly

- Cast aluminum, satin finish (P6817 also available in black)
- White glass - open cast frame with white tempered glass
- Louver/glass - Cast louver that directs all light downward with a white tempered glass behind it
- Faceplates held on with four screws, and gasketed for weather resistance and no light leaks

Housing

- Cast aluminum
- Two 1/2" I.P. conduit entries
- For indoor and outdoor use
- For poured concrete and masonry installations only

Electrical

- Medium base porcelain lampholder
- Separate outlet boxes (by others) must be used for multiple unit installations

Labeling

- UL-CUL wet location listed