

Hide-a-lite

Undercabinet Mounted • Damp Location Listed **PROGRESS LED**

Description:

Hide-A-Lite Collection 9" LED 5-CCT Linear Undercabinet Light

Specifications:

- Dimmable to 10% brightness (See Dimming Notes)
- 8.78 in W, 0.12 in ht., 3.02 in depth
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

Performance:

Number of Modules	1
Input Power	4 W
Input Voltage	120 VAC
Input Frequency	60 Hz
Lumens/LPW (Delivered)	228/57 (LM-79)
CCT	2700 K
	3000 K
	3500 K
	4000 K
	5000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cCSAus Damp Location Listed
	Meets California Title 24 JA8-2019

P700024-028-CS



Dimensions:

Width: 9.02 in
 Depth: 3-1/4 in
 Height: 1.05 in




P700024-028-CS

Photometrics:

ELECTRICAL DATA	P700024-028-CS
Input Voltage	120 VAC
Input Frequency	60 Hz
THD	<20%
EMI/RFI	FCC Title 47, Part 15, Class B
Operating Temperature	-25 °C to 30 °C
Dimming	Yes*
Over-voltage, over-current, short-circuit protected	
*See Dimming Notes for more information	

P700024-028-CS

LED Light Engine: 2700 K 90 CRI
 System Wattage: 4 W
 Fixture delivered lumens: 228 lm
 Fixture Efficacy: 57 Lum/Watt

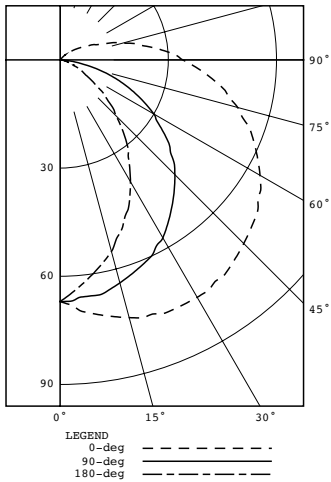

CANDELA		DISTRIBUTION					FLUX
0.0	45.0	90.0	135.0	180.0			
0	67.0	67.0	67.0	67.0	67.0	6	
5	70.0	69.0	66.0	64.0	63.0	18	
15	74.0	71.0	64.0	57.0	55.0	18	
25	76.0	71.0	60.0	49.0	45.0	28	
35	75.0	69.0	53.0	39.0	33.0	34	
45	72.0	64.0	45.0	28.0	22.0	35	
55	67.0	58.0	35.0	17.0	12.0	33	
65	60.0	49.0	24.0	8.0	6.0	28	
75	51.0	39.0	12.0	2.0	2.0	21	
85	40.0	28.0	2.0	0.0	0.0	14	
90	34.0	22.0	0.0	0.0	0.0		
95	29.0	17.0	0.0	0.0	0.0	9	
105	18.0	8.0	0.0	0.0	0.0	5	
115	10.0	4.0	0.0	0.0	0.0	2	
125	5.0	1.0	0.0	0.0	0.0	1	
135	2.0	0.0	0.0	0.0	0.0	0	
145	0.0	0.0	0.0	0.0	0.0	0	
155	0.0	0.0	0.0	0.0	0.0	0	
165	0.0	0.0	0.0	0.0	0.0	0	
175	0.0	0.0	0.0	0.0	0.0	0	
180	0.0	0.0	0.0	0.0	0.0	0	

Test 20.00603 Test Date 05/19/2020

P700024-028-CS

Dimming Notes:

P700024-028-CS is designed to be compatible with many Triac/Forward Phase ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Eaton AAL06

IDevices IDEV009

Leviton_Trimatron 6681

Leviton IPI06-1LZ

Leviton 6672

Leviton 6674

Lutron NTEVL-300

Lutron DVELV-300P

Lutron DVCL-253P

Lutron Caseta Wireless

Lutron AYCL-153P

Lutron SCL-153P

Lutron TGCL-153-PH-WH

Lutron MACL-153M

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.