

Curve LED

Wall-Mount Mounted • Damp Location Listed **PROGRESS LED**

Description:

Curve LED One-Light White Opal Acrylic Modern Style Wall Sconce Light

Specifications:

- Opal Acrylic Flat Round
- Dimmable to 10% brightness (See Dimming Notes)
- Canopy covers a standard 4" recessed outlet box: 4.75 in W., 7.5 in ht., 0.75 in depth
- Mounting backplate for outlet box included
- 6 in of wire supplied
- Americans With Disabilities Act (ADA) compliant

Performance:

Number of Modules	1
Input Power	10 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	744/74 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	50000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Warranty	5-year Limited Warranty
Labels	cETLus Damp Location Listed Meets California Title 24 JA8-2019


P710102-060-30



Dimensions:

Width: 8 in
 Extends: 3-5/8 in
 Height: 8 in
 H/CTR: 4 in

Opal Acrylic Flat Round
 Length: 2.69 in
 Width: 8 in
 Height: 8 in

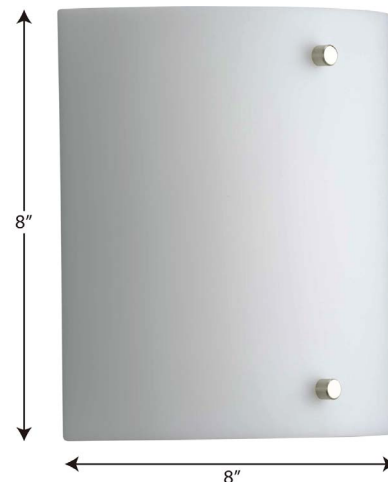

P710102-060-30

Dimming Notes:

P710102-060-30 is designed to be compatible with many Triac/ELV controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Leviton_6672

Leviton_6674

Lutron_NTEVL-300

Lutron_DVELV-300P

Lutron_DVCL-253P

Lutron_TGCL-153-PH-WH

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.