



Project: _____

Fixture Type: _____

Location: _____


Contact: _____

P710107-009

Elara

Elara Collection Two-Light New Traditional Brushed Nickel Wall Light

Category: Wall Brackets
Finish: Brushed Nickel (Plated)
Construction: Steel Construction

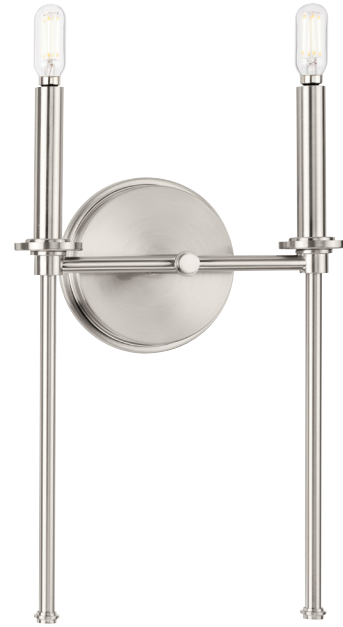

Width: 10-3/8 in
Extends: 4-3/8 in
Height: 16-5/8 in
H/CTR: 5-1/2 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Wall mounted	6 inches of wire supplied	(2) Candelabra Base (E12) Socket	cULus Damp Location Listed
Mounting backplate for outlet box included	120 VAC	Lamp Type B10	1-year Limited Warranty
Canopy covers a standard 4" recessed outlet box: 5.75" W., 1" ht., 5.75" depth		Incandescent: 60-watt MAX per socket LED: 12.5-watt MAX per socket Fully dimmable with dimmable bulbs	