


Project: _____
 Fixture Type: _____
 Location: _____
 Contact: _____

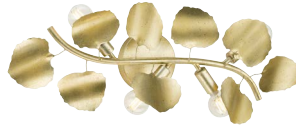

P710123-176 Laurel

Laurel Collection Four-Light Gilded Silver Transitional Wall Bracket

Category: Wall Brackets
Finish: Gilded Silver (Hand Painted)
Construction: Steel Housing

Width: 9 in
 Extends: 4-3/8 in
 Height: 24-1/2 in (Mounted Vertical)
 H/CTR: 12-1/4 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Wall mounted	6 inches of wire supplied	(4) Candelabra Base (E12) Socket	cETLus Damp Location Listed
Mounting plate for outlet box included	120 VAC	Lamp Type Incandescent: 60-watt MAX per socket LED: 12.5-watt MAX per socket	1-year Limited Warranty
Canopy covers a standard 4" recessed outlet box: 4.75" W., 0.75" ht., 4.75" depth		Fully dimmable with dimmable bulbs.	