

Project: _____

Fixture Type: _____

Location: _____

Contact: _____

P710131-31M
Cornett

Cornett Collection One-Light Matte Black Contemporary Wall Sconce


Category: Wall Brackets
Finish: Matte Black (Painted)
Construction: Steel Housing
Glass/Shade: Matte Black, Painted White Inside Metal Cone



Width: 4-1/2 in
Extends: 20 in
Height: 19 in
H/CTR: 9-9/16 in

Matte Black, Painted White Inside Metal Cone
Width: 2-1/2 in
Height: 3-13/16 in

MOUNTING	ELECTRICAL	LAMPING	ADDITIONAL INFORMATION
Wall mounted	6 inches of wire supplied	(1) Medium Base (E26) Socket	cULus Damp Location Listed
Mounting backplate for outlet box included	120 VAC	Lamp Type 15 W max LED	1-year Limited Warranty
Canopy covers a standard 4" recessed outlet box: 4.5" W., 7.5" ht., 1" depth	Switch Type: On/Off	Fully dimmable with dimmable bulbs.	

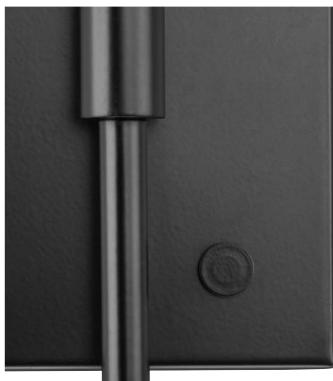

On/Off touch switch

