

## Hard-Nox Collection One-Light Wall Sconce Wall Mounted • Damp Location Listed

### Description:

Energy efficient, long-lasting lamps. Clear prismatic DR acrylic diffuser. Can be wall mounted. 120V NPF ballast. UL listed for damp locations.

- White finish.
- Impact resistant.
- Clear prismatic polycarbonate diffuser.


### Specifications:

- White (-68) (White)
- Steel Construction
- Clear prismatic polycarbonate
- Fully dimmable with dimmable bulbs.
- Chassis covers a standard 4" recessed outlet box
- Slots in back plate
- 6 in of wire supplied

### Performance:

Number of Lamps	1
Input Power	13 W
Input Voltage	120 V
Warranty	1 year warranty
Labels	UL-CUL Damp Location Listed

## P7124-68

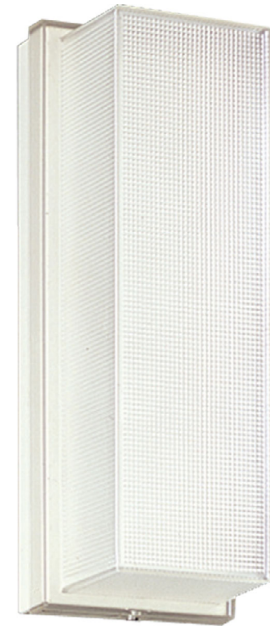

### Dimensions:

Width: 4.25 in  
Height: 12.25 in  
Depth: 4.25 in  
H/CTR: 6.125 in

Clear prismatic polycarbonate