

LED CTC COMM

Flush-Mount Mounted • Damp Location Listed PROGRESS LED



Description:

One-Light Brushed Nickel LED close-to-ceiling. Surface mount round with clean modern lines and white acrylic diffuser. DC LED light engine with 1765 delivered lumens at 3000K and 90+ CRI.

Specifications:

- White acrylic Diffuser
- Brushed Nickel finish.
- Steel construction.
- Dimmable to 10% brightness with many Forward and Reverse Phase dimmers.
- 3000k color temperature.
- TM-21 54,000 hour life.
- Meets California Title 24 - JA8 - 2016.
- 1,765 lumens (delivered).
- Dimmable to 10% brightness (See Dimming Notes)
- Ceiling pan covers a standard 4" recessed outlet box: 17.625 in W., 0.5 in ht., 17.625 in depth
- Ceiling pan
- 6 in of wire supplied

Performance:

Number of Modules	1
Input Power	30 W
Input Voltage	120 V
Input Frequency	60 Hz
Lumens/LPW (Delivered)	1,765/58.8 (LM-79)
CCT	3000 K
CRI	90 CRI
Life (hours)	54000 (L70/TM-21)
EMI/RFI	FCC Title 47, Part 15, Class B
Max. Operating Temp	30 °C
Warranty	5-year Limited Warranty
Labels	ETL Damp Location Listed ENERGY STAR® qualified Meets California Title 24 JA8-2016


P7250-0930K9



Dimensions:

Diameter: 17-3/4 in
Height: 4-3/4 in

White acrylic Diffuser
Width: 16-3/8 in
Height: 4-1/4 in

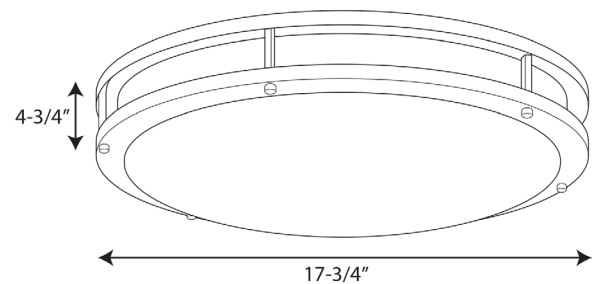

P7250-0930K9

Dimming Notes:

P7250-0930K9 is designed to be compatible with many Triac/Forward Phase ELV/Reverse Phase controls.

The following is a partial list of known compatible dimmer controls.

Dimming Controls:

Lutron_Nova T VTELV-300

Leviton_6681

Leviton_SureSlide 6672

Leviton_SureSlide 6674

Lutron_Ariadni AYCL-153P

Lutron_Ariadni AYLV-600P

Lutron_NTLV-600

Lutron_Maestro MAELV-601

Leviton_Renoir II AWRMG-EAW

Lutron_Nova N-600

Dimming capabilities will vary depending on the dimmer control, load, and circuit installation.

Always refer to dimmer manufacturer instructions or a controls specialist for specific requirements.

Dimmer control brand names where identified above are trade names or registered trademarks of each respective company.