



Incandescent

4" Line Voltage

Recessed

Alzak Cone

IC & Non-IC

Type _____

-31

P8049

Finish


Catalog No. **Black Alzak**

Dimensions (Inches)

A

P8049 -31

5

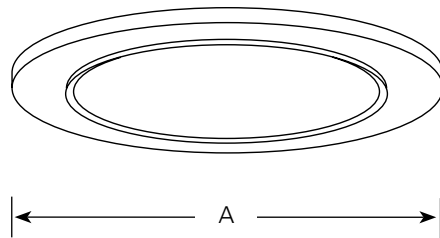

Lamp Wattage

Housing	IC	Non-IC
P831-AT	75PAR16/75R20/50PAR20	75PAR16/75R20/50PAR20
P830-TG	N/A	75PAR16/75R20/50PAR20
P832-TG	N/A	75PAR16/75R20/50PAR20

Specifications:

Flange

- Flange is Black Alzak (-31) finish
- No light leaks around trim flange

Trim

- Steel construction
- Lamp tilts 20 degrees., 360-degree positioning
- Insulation must be 3" from housing
- Socket mounts to trim for optimum performance and consistent lamp position

Options

- None

Labels

- UL-CUL damp location listed