


Type _____
 -09 -28 -31
 P8715

Catalog No.	Finish			Dimensions (Inches)	
	Brushed			A	B
	Nickel	White	Black		
P8715	-09	-28	-31	5-1/2	19-1/4

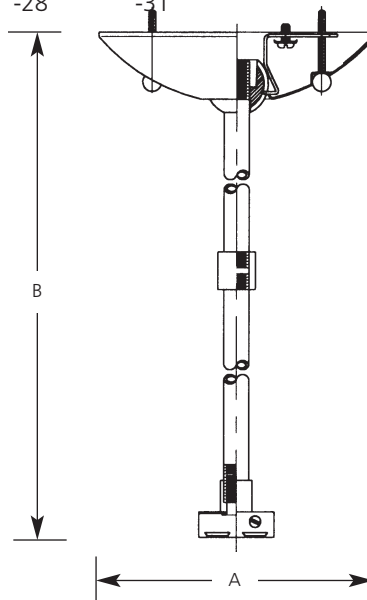

Specifications:

General

- Steel construction
- Die-cast aluminum swivel ball
- Includes (1) 12" stem and (1) 6" stem
- For flat ceilings or sloped ceilings up to 45 degrees
- Stem assembly is horizontally adjustable up to 358°
- Must be used with at least one P8718 for supplying power and support
- Will support up to 48 pounds when used with (1) P8718

Mounting

- Mounts directly to sheetrock or T-bar ceilings

Labeling

- For use with Progress Lighting track systems only

Options

- Specify after Catalog No.:
 Brushed Nickel (-09)
 White (-28)
 Black (-31)