

Project: _____

Fixture Type: _____

Location: _____


Contact: _____

P900012-009 Ridgecrest

Infuse an abundance of sophisticated versatile light to an commercial or residential setting with this brushed nickel four-head track light fixture. Multi-directional lamp heads provide design flexibility and illuminate typically hard-to-reach areas. The round ceiling plate, thin metal bar, and light bases are coated in a beautiful brushed nickel finish. Each lamp head features a crisp frosted glass shade for soft, general ambient light.


- Each lamp head features a crisp frosted glass shade for soft, general ambient light.
- The round ceiling plate, thin metal bar, and light bases are coated in a beautiful brushed nickel finish.
- Multi-directional lamp heads provide design flexibility and illuminate typically hard-to-reach areas.
- Ideal for any sitting room, hallway, or foyer.
- Perfect for transitional or modern settings.
- Measures 5-inch width by 7-1/8-inch height.
- Uses four medium base bulbs that are sold separately (60w max - LED or incandescent).
- Able to be fully dimmable with dimmable bulbs.
- Includes installation instructions and mounting hardware.
- Progress Lighting products are designed for exceptional quality, reliability, and functionality.

Category: Directionals
Finish: Brushed Nickel (Plated)
Construction: Steel Construction
Glass/Shade: Etched glass Cylindrical Shade

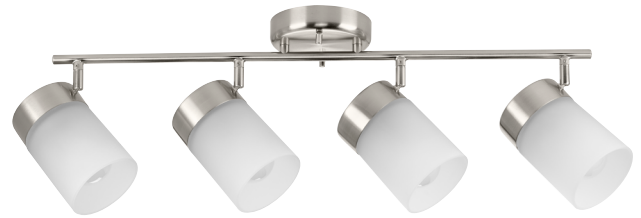

Width: 5 in
 Height: 7-1/8 in
 Depth: 26-1/8 in

Etched glass Cylindrical Shade
 Width: 3-3/4 in
 Height: 4-1/2 in

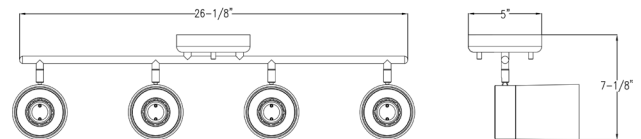

| MOUNTING | ELECTRICAL | LAMPING | ADDITIONAL INFORMATION |
|-----------------------------------|--|---|----------------------------|
| Ceiling mounted | Prewired | Quantity: Four 60 W max. Medium Base or LED equivalent | CULus Damp Location Listed |
| Canopy 5" W., 0.18" ht., 5" depth | 6 inches of wire supplied 120 V | E26 base sockets | 1-year Limited Warranty |