

PCBO SERIES

Walkway Lighting

Specifications:

Construction:

- Extruded aluminum square or round housing, with tamper resistant hardware; Flat top, for round. Single screw access for top relamping.
- Sealed one-piece, clear acrylic lens; Specular anodized aluminum optical systems; dual reflector or tube optics
- Concealed, galvanized steel anchor base; Four ½" x 10" anchor bolts
- Durable Lektrocote® TGIC thermoset polyester powder coat paint finish assures long life and maintenance-free service

Electrical:

- Universal voltage (120-277V) drivers with +/- 10% tolerance, starting temperature rated at -20°C
- Rotatable LED assembly adjustment for ideal placement and aiming of symmetric light pattern
- 24 high brightness LEDs at 500 mA deliver symmetric distribution at 46 Watts
- 12 high brightness LEDs at 700 mA deliver asymmetric distribution at 31 Watts
- 4000K color temperature

Warranty:

5 year limited warranty for LED system.

Listing/Certification:

The luminaire is listed to UL 1598 for use in wet locations.

Catalog number:


Series	Distribution	Finish
PCBOR - Bollard Round	ASY - 12 LEDS@ 31W	BZ - Bronze
PCBOS - Bollard Square	SYM - 24LEDs@ 46W	BL - Black

Photometry:

Images:




Dimensions & Mounting

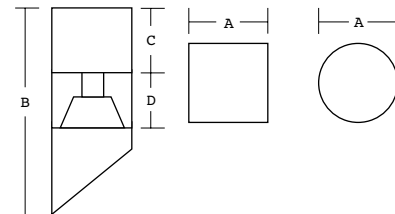

	A	B	C	D	Weight
Square	6.75" sq.	42.0"	6.0"	4.0"	41 lbs
	171 mm	1067 mm	152 mm	102 mm	19 kg
Round	7.0" dia	42.0"	6.0"	4.0"	41 lbs
	178 mm	1067 mm	152 mm	102 mm	19 kg

ASYMMETRIC DISTRIBUTION, 3500K

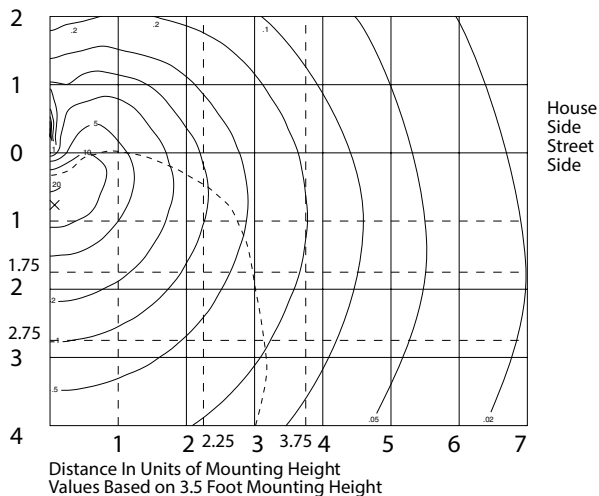

SYMMETRIC DISTRIBUTION, 3500K

