

# PCIRT-LED Series

Indoor Lensed LED Troffer

## Specifications:

### Features:

- Residential or Commercial
- High Efficiency LED, 50,000 Hour Life
- Latching Door with Prismatic Lens
- For Use in T-bar Ceiling
- 3500K and 4000K color temperatures
- 0-10V dimming standard
- Universal input voltage 120-277 VAC, 50/60Hz
- Damp Location and IC Rated
- DesignLights Consortium® (DLC) qualified; see [www.designlights.org](http://www.designlights.org)

### Compliances:

PCIRT Series are built to UL 1598 standards and UL listed Damp location labeling is standard. IC Rated. DesignLights Consortium® (DLC) qualified. Please refer to the DLC website for specific product qualifications at [www.designlights.org](http://www.designlights.org).

### Warranty:

5 year warranty (Terms and Conditions Apply)


### Performance:

Catalog Number	Watts	Lumens	CCT	CRI
PCIRT-LED-22-35K	26.5W	3000	3500K	> 80
PCIRT-LED-22-40K	26.5W	3000	4000K	> 80
PCIRT-LED-24-35K	34W	4060	3500K	> 80
PCIRT-LED-24-40K	34.5W	4005	4000K	> 80

### Images:



### Dimensions:

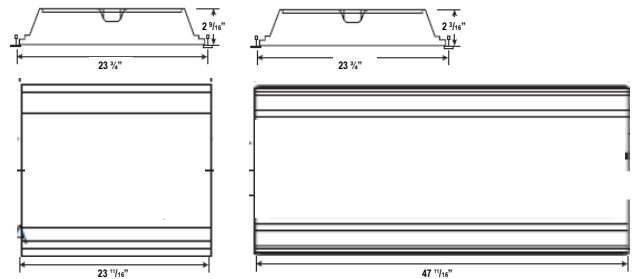

### Catalog Number:

Base	Lamp Type	Lamp Size	Color Temperature
PCIRT	LED	22 - 2x2 24 - 2x4	35K - 3500K 40K - 4000K