

PEOEU SERIES

Decorative LED AC/Emergency Light

Specifications:

Description:

The PEOEU Series offers LED performance in “normally on” AC and emergency lighting modes. The unit has a prismatic polycarbonate refractor with a durable die-cast aluminum housing available with durable powder coated dark bronze finish. The housing is fully sealed and gasketed. It is designed for wall mounting with a universal K/O pattern in the back-plate for installation to most standard size junction boxes. Illumination is provided by 2 high power LEDs driven at 3 watts each. LED color at 5500K.

Features:

- LED life-cycle of more than 10 years
- Includes self-diagnostic feature to monitor proper operation
- Universal 100-300 VAC input
- Includes long-life 4.8 VDC Nickel Cadmium battery for UL recognized 90 minute operation
- Full re-charge within 24 hours
- Water-proof test switch and AC-On indicator
- Optional photo-cell for normally-on operation

Application:

The PEOEU Series can be applied in areas that are susceptible to rain and severe moisture, such as parking decks and outdoor commercial applications.

Input Power Requirements:

		120V		277 V	
PEOEU-EM	AC ON	9.00 W	0.13 A	8.89 W	0.07 A
	AC OFF	2.04 W	0.04 A	2.15 W	0.02 A
PEOEU-EM -HTR	AC ON	18.47 W	0.21A	58.90 W	0.25 A
	AC OFF	11.51 W	0.11 A	52.15 W	0.20 A


Compliances:

- Listed to UL924 Wet Location
- NFPA 101 and NFPA 70
- OSHA


Catalog number:

Base	Emergency	Finish	Option
PEOEU	EM - Emergency Battery	20 - Bronze	HTR - Heater

Images:

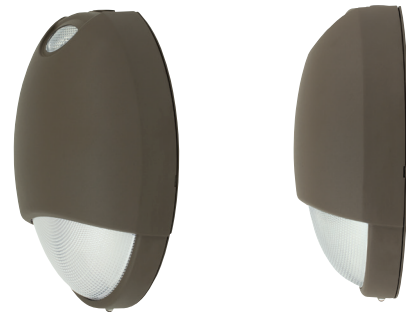

Dimensions:

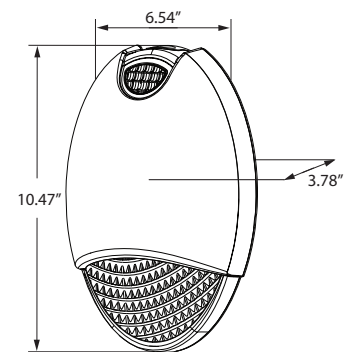

Warranty:

2 year full unit warranty