

Multifamily/Commercial

Fixture Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Bollard - PMBO

Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with high-impact, polycarbonate lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 1,825 to 3,290 nominal lumens
- Anchor bolt mounted
- Anchor bolt kit ordered separately; use PMBOR-ACSY-AB


Performance:

Input Power	23 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	1,970/2685/3240/145 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10VDC
Ingress Protection	IP65
Operating Temperature	-40 °C to 55 °C
THD	<20%
Power Factor	>0.90

PMBOR-FLT-LS-CS-BZ



Dimensions:

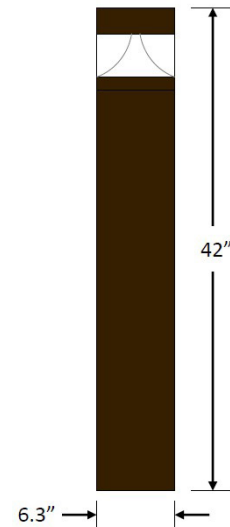

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	13W	14W	13W	18W	19W	18W	23W	22W	23W
Lumens	1827	1974	1942	2507	2686	2665	3090	3244	3296
Efficacy	139	144	148	138	145	146	134	145	144