

Multifamily/Commercial

Fixture Mounted • Wet Location Listed **PROGRESS LED**

Description:

LED Outdoor Commercial Bollard - PMBO


Specifications:

- Rugged die-cast aluminum housing
- Dark Bronze powder coat finish with high-impact, polycarbonate lens
- CCT field selectable feature offers 3000K, 4000K and 5000K options
- Field selectable lumen range from 1,700 to 3,045 nominal lumens
- Anchor bolt mounted
- Anchor bolt kit ordered separately; use PMBOS-ACSY-AB


Performance:

Input Power	23 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	1790/2450/3045/134 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Wet Location Listed
Dimming	0-10V DC
Ingress Protection	IP65
Operating Temperature	-40 °C to 55 °C
THD	<20%
Power Factor	>0.90

PMBOS-FLT-LS-CS-BZ

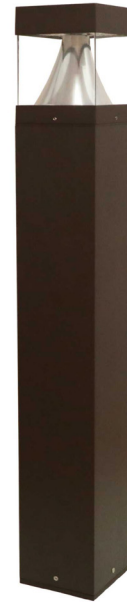

Dimensions:

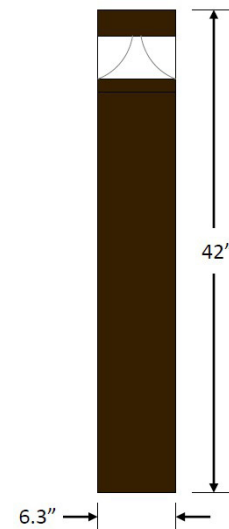

	Low Setting			Mid Setting			High Setting		
	3000K	4000K	5000K	3000K	4000K	5000K	3000K	4000K	5000K
Watts	13W	14W	13W	18W	18W	19W	23W	23W	23W
Lumens	1702	1790	1805	2303	2450	2459	2887	3047	3041
Efficacy	128	132	135	125	134	133	125	135	131