

Multifamily/Commercial

Ceiling Mounted • Damp Location Listed **PROGRESS LED**

Description:

LED Commercial Strip Light - PMISS

Specifications:

- Heavy gauge steel housing
- White powder coat finish with frosted PMMA lens
- CCT field selectable feature offers 3500K, 4000K and 5000K options
- Field selectable lumen range from 3,630 to 5,200 nominal lumens
- Backup emergency driver installed (11W EM provides 1,625 lumens) ¹

Performance:


Input Power	36 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	3,630/4315/5200/135 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Damp Location Listed And Feed Through Branch Wiring
Dimming	0-10VDC
Operating Temperature	-20 °C to 50 °C
THD	<20%
Power Factor	>0.90

PMISS-4-LS-CS-EM



Dimensions:

Length: 47-1/4 in
 Width: 3-1/4 in
 Height: 3-1/2 in

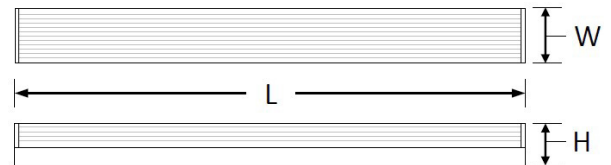

	Low Setting			Mid Setting			High Setting		
	3500K	4000K	5000K	3500K	4000K	5000K	3500K	4000K	5000K
Watts	26W	25W	26W	31W	30W	31W	35W	34W	35W
Lumens	3690	3631	3722	4336	4317	4389	4876	5203	4908
Efficacy	143	143	144	140	143	142	138	152	139

¹ - Suitable for ambient temperatures above 10°C (50°F)