

Description:

PMISW-4-LS-CS-EM-OS

LED Stairwell Strip Light - PMISW

Specifications:

- Painted steel housing with frosted PMMA lens
- CCT field selectable feature offers 3500K, 4000K and 5000K options
- Field selectable lumen range from 4,200 to 6,495 nominal lumens
- Backup emergency driver installed (11W EM provides 1,625 lumens) ¹
- Occupancy dimming sensor standard for stairwell lighting control
- Passive infrared sensor features include on/off only (additional control capability is available with use of accessory remote, sold separately; part number: PMISW-OS-REMOTE. One remote can program multiple fixtures)


Performance:

Input Power	47 W
Input Voltage	Universal 120-277 VAC
Input Frequency	50/60 Hz
Lumens/LPW (Delivered)	4,310/4940/6495/129 (LM-79)
Lumen selectable values based on 4000K selection	
CRI	80 CRI
Life (hours)	50000
EMI/RFI	FCC Part 15, Class A
Warranty	5-year Limited Warranty
Labels	cULus Damp Location Listed And Feed Through Branch Wiring
Dimming	0-10VDC
Operating Temperature	-20 °C to 50 °C
THD	<20%
Power Factor	>0.90



Dimensions:

Length: 48 in
 Width: 4 in
 Height: 4-1/2 in

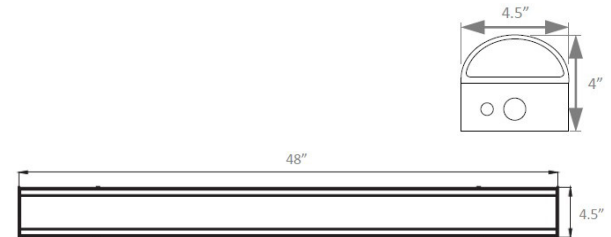

	Low Setting			Mid Setting			High Setting		
	3500K	4000K	5000K	3500K	4000K	5000K	3500K	4000K	5000K
Watts	29W	28W	29W	34W	33W	34W	46W	45W	46W
Lumens	4245	4311	4208	4820	4941	4792	6226	6499	6056
Efficacy	145	152	143	143	150	141	135	146	130

¹ - Suitable for ambient temperatures above 10°C (50°F)