

Description:

LED Stairwell Strip Light - PMISW

Specifications:

- Painted steel housing with frosted PMMA lens
- CCT field selectable feature offers 3500K, 4000K and 5000K options
- Field selectable lumen range from 4,200 to 6,495 nominal lumens
- Occupancy dimming sensor standard for stairwell lighting control
- Passive infrared sensor features include on/off only (additional control capability is available with use of accessory remote, sold separately; part number: PMISW-OS-REMOTE. One remote can program multiple fixtures)

Performance:


| | |
|--|---|
| Input Power | 47 W |
| Input Voltage | Universal 120-277 VAC |
| Input Frequency | 50/60 Hz |
| Lumens/LPW (Delivered) | 4,310/4940/6495/129 (LM-79) |
| Lumen selectable values based on 4000K selection | |
| CRI | 80 CRI |
| Life (hours) | 50000 |
| EMI/RFI | FCC Part 15, Class A |
| Warranty | 5-year Limited Warranty |
| Labels | cULus Damp Location Listed And Feed Through Branch Wiring |
| Dimming | 0-10VDC |
| Operating Temperature | -20 °C to 50 °C |
| THD | <20% |
| Power Factor | >0.90 |

PMISW-4-LS-CS-OS



Dimensions:

Length: 48 in
 Width: 4 in
 Height: 4-1/2 in

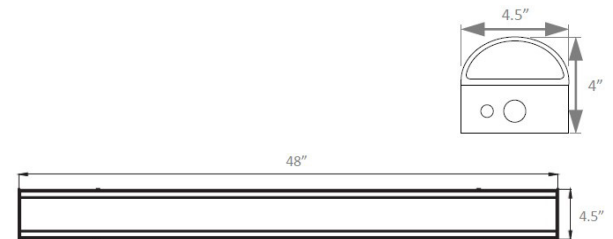

| | Low Setting | | | Mid Setting | | | High Setting | | |
|----------|-------------|-------|-------|-------------|-------|-------|--------------|-------|-------|
| | 3500K | 4000K | 5000K | 3500K | 4000K | 5000K | 3500K | 4000K | 5000K |
| Watts | 29W | 28W | 29W | 34W | 33W | 34W | 46W | 45W | 46W |
| Lumens | 4245 | 4311 | 4208 | 4820 | 4941 | 4792 | 6226 | 6499 | 6056 |
| Efficacy | 145 | 152 | 143 | 143 | 150 | 141 | 135 | 146 | 130 |